



Powering Business Worldwide

pe.eaton.com

Type Visi-Flex Disconnect Switch Component - Switch Only

2607D66G14

UPC:786679612521

Dimensions:

- **Height:** 7.2 IN
- **Length:** 8.3 IN
- **Width:** 6.7 IN

Weight:5.9 LB

Notes:External operating handle, shaft and no-fuse kit required. Rated 600 volts. Standard 60Aere switch has same dimensions as 100Aere Visi-Flex switch.

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.


Specifications:

- **Type:** Disconnect switch
- **Amperage Rating:** 60A
- **Fuse Configuration:** Non-fusible
- **Max Hp Rating:** 7-1/2 hp at 120 Vac, 20 hp at 240 Vac, 40 hp at 480 Vac, 50 hp at 600 Vac, 10 hp at 250 Vdc
- **Switch Type:** Visi-Flex DE-ION
- **Trip Type:** Model A trip
- **Wire Size:** #14-1/0 Cu

Supporting documents:

- [Eatons Volume 2-Commercial Distribution](#)
- [Eaton Specification Sheet - 2607D66G14](#)

Certifications:

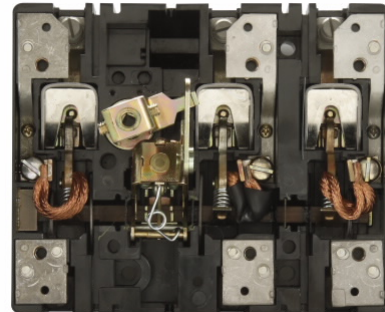

- UL Listed

Product compliance: No Data

© 2016 Eaton. All rights reserved.