



Powering Business Worldwide

[pe.eaton.com](http://pe.eaton.com)

## Industrial Control Transformer

**C1500K4C**

**UPC:**786680001888

### Dimensions:

- **Height:** 5.669 IN
- **Length:** 7.52 IN
- **Width:** 6.732 IN

**Weight:**33 LB

**Notes:**Epoxy resin impregnated coil design, 50/60 Hz operation, 180°C insulation system

### Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Specifications:


- **Coil Material:** Copper windings
- **Design:** MTK
- **Primary Voltage:** 550/575/600V
- **Secondary Voltage:** 110/115/120V
- **Tap Size:** None
- **Temperature Rating:** 115°C
- **Type:** Industrial Control Transformer
- **Volt Ampere Rating:** 1500 VA

### Supporting documents:

- [Eaton's Volume 7-Logic Control, Operator Interface and Connectivity Solutions](#)
- [Industrial Control Transformer - C1500K4C](#)
- [Eaton Specification Sheet - C1500K4C](#)

### Certifications:

- UL Listed
- cUL Certified
- CSA Certified

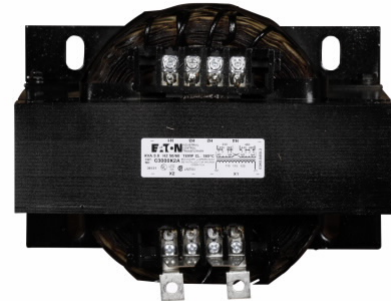

**Product compliance:**

- RoHS Compliant

---

© 2016 Eaton. All rights reserved.