



Powering Business Worldwide

pe.eaton.com

Molded Case Engine Generator Circuit Breaker

FG3090

UPC:786679269725

Dimensions:

- **Height:** 5 IN
- **Length:** 7 IN
- **Width:** 5 IN

Weight:4 LB

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:


- **Amperage Rating:** 90A
- **Number Of Poles:** Three-pole
- **Series:** Series C
- **Terminals:** Line and load
- **Trip Type:** Thermal magnetic
- **Feed Type:** Reverse
- **Frame:** FG-frame
- **Generator Rating:** 32 kVA/26 kW at 240V, 65 kVA/52 kW at 480V, 81 kVA/65 kW at 600V
- **Pickup:** Fixed

Supporting documents:

- [Eatons Volume 4-Circuit Protection](#)
- [Eaton Specification Sheet - FG3090](#)

Certifications:

- CSA Std. C22.2 No. 5
- IEC 947-2
- UL Listed
- CSA Certified
- IEC Rated

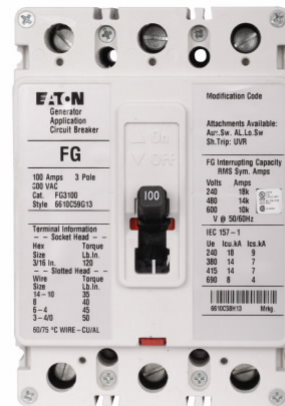

- UL 489

Product compliance: No Data

© 2016 Eaton. All rights reserved.