



Powering Business Worldwide

pe.eaton.com

Molded Case Engine Generator Circuit Breaker

FG3175

UPC:782114415306

Dimensions:

- **Height:** 5 IN
- **Length:** 7.5 IN
- **Width:** 5 IN

Weight:3 LB

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:


- **Amperage Rating:** 175A
- **Number Of Poles:** Three-pole
- **Series:** Series C
- **Terminals:** Line and load
- **Trip Type:** Thermal magnetic
- **Feed Type:** Reverse
- **Frame:** FG-frame
- **Generator Rating:** 63 kVA/51 kW at 240V, 126 kVA/101 kW at 480V, 158 kVA/126 kW at 600V
- **Pickup:** Fixed

Supporting documents:

- [Eaton's Volume 4-Circuit Protection](#)
- [Eaton Specification Sheet - FG3175](#)

Certifications:

- UL Listed
- IEC Rated
- IEC 947-2
- UL 489
- CSA Certified

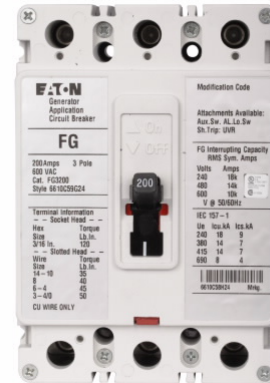

- CSA Std. C22.2 No. 5

Product compliance: No Data

© 2016 Eaton. All rights reserved.