



Powering Business Worldwide

pe.eaton.com

Molded Case Engine Generator Circuit Breaker

FG3050

UPC:786679269640

Dimensions:

- **Height:** 5 IN
- **Length:** 7 IN
- **Width:** 5 IN

Weight:4 LB

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:


- **Amperage Rating:** 50A
- **Number Of Poles:** Three-pole
- **Series:** Series C
- **Terminals:** Line and load
- **Trip Type:** Thermal magnetic
- **Feed Type:** Reverse
- **Frame:** FG-frame
- **Generator Rating:** 18 kVA/14 kW at 240V, 36 kVA/29 kW at 480V, 45 kVA/36 kW at 600V
- **Pickup:** Fixed

Supporting documents:

- [Eaton's Volume 4-Circuit Protection](#)
- [Eaton Specification Sheet - FG3050](#)

Certifications:

- CSA Std. C22.2 No. 5
- UL 489
- IEC 947-2
- IEC Rated
- UL Listed

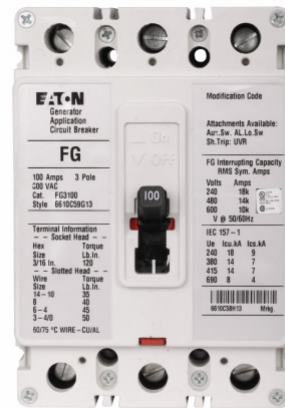

- CSA Certified

Product compliance: No Data

© 2016 Eaton. All rights reserved.