



Powering Business Worldwide

pe.eaton.com

Molded Case Engine Generator Circuit Breaker

FG3035

UPC:786679269589

Dimensions:

- **Height:** 5 IN
- **Length:** 7 IN
- **Width:** 5 IN

Weight:4 LB

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:


- **Amperage Rating:** 35A
- **Number Of Poles:** Three-pole
- **Series:** Series C
- **Terminals:** Line and load
- **Trip Type:** Thermal magnetic
- **Feed Type:** Reverse
- **Frame:** FG-frame
- **Generator Rating:** 13 kVA/10 kW at 240V, 25 kVA/20 kW at 480V, 32 kVA/25 kW at 600V
- **Pickup:** Fixed

Supporting documents:

- [Eatons Volume 4-Circuit Protection](#)
- [Eaton Specification Sheet - FG3035](#)

Certifications:

- IEC Rated
- UL Listed
- IEC 947-2
- CSA Std. C22.2 No. 5
- UL 489

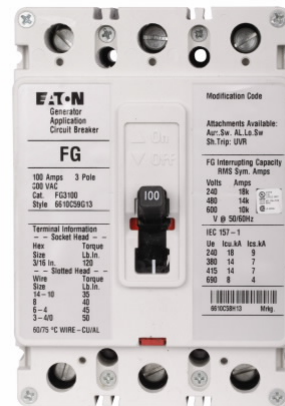

- CSA Certified

Product compliance: No Data

© 2016 Eaton. All rights reserved.