



Powering Business Worldwide

pe.eaton.com

Industrial Control Transformer

C1000K2CXX

UPC:786680004759

Dimensions:

- **Height:** 4.449 IN
- **Length:** 7.874 IN
- **Width:** 5.236 IN

Weight:26.4 LB

Notes:Epoxy resin impregnated coil design, 50/60 Hz operation, 180°C insulation system

Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Specifications:


- **Coil Material:** Copper windings
- **Design:** MTK
- **Modification 1:** No secondary fuse clips
- **Primary Voltage:** 240V X 480V
- **Secondary Voltage:** 120 X 240V
- **Tap Size:** None
- **Temperature Rating:** 115°C
- **Type:** Industrial Control Transformer
- **Volt Ampere Rating:** 1000 VA

Supporting documents:

- [Eatons Volume 7-Logic Control, Operator Interface and Connectivity Solutions](#)
- [Eaton Specification Sheet - C1000K2CXX](#)

Certifications:

- CSA Certified
- cUL Certified
- UL Listed

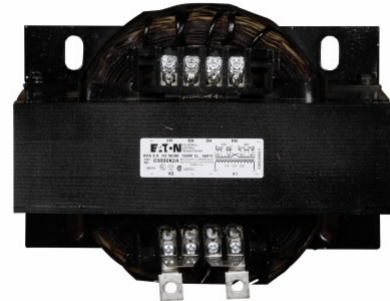

Product compliance:

- RoHS Compliant

© 2016 Eaton. All rights reserved.