



Powering Business Worldwide

pe.eaton.com

Inductive Global Proximity Sensor

E57-08GE03-C

UPC:782116469475

Dimensions:

- **Height:** .31 IN
- **Length:** 1.81 IN
- **Width:** .31 IN

Warranties:


- 1 year

Specifications:

- **Type:** Inductive Global Proximity Sensor
- **Accuracy:** <1.0% sensing range
- **Connection:** 2m cable
- **Contact Rating:** 100 mA at 10-30 Vdc
- **Cable Type:** PVC
- **Contact Configuration:** NPN open collector, NO
- **Cord Length:** 79.2 FT
- **Diameter:** .314960632 MM
- **Enclosure Material:** Nickel plated brass
- **Environmental Rating:** IP67, IP69K
- **Input Voltage:** 10-30 Vdc
- **Led Indicators:** Output ON
- **Maximum Dc Current:** 100 mA
- **Number Of Wires:** 3-wire
- **Operating Mode:** Unshielded
- **Operating Temperature:** 32° to 104°F
- **Protection:** S/C
- **Series:** E57

Supporting documents:

- [Eatons Volume 8-Sensing Solutions](#)
- [Global Series inductive proximity sensors](#)
- [Eaton Specification Sheet - E57-08GE03-C](#)

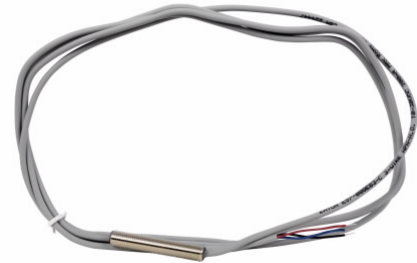

Certifications: No Data

Product compliance: No Data

© 2016 Eaton. All rights reserved.