



Powering Business Worldwide

[pe.eaton.com](http://pe.eaton.com)

## Molded Case Engine Generator Circuit Breaker

**FG3015**

**UPC:**786679269503

### Dimensions:

- **Height:** 5 IN
- **Length:** 7 IN
- **Width:** 5 IN

**Weight:**4 LB

### Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Specifications:


- **Amperage Rating:** 15A
- **Number Of Poles:** Three-pole
- **Series:** Series C
- **Terminals:** Line and load
- **Trip Type:** Thermal magnetic
- **Feed Type:** Reverse
- **Frame:** FG-frame
- **Generator Rating:** 5 kVA/4 kW at 240V, 11 kVA/9 kW at 480V, 14 kVA/11 kW at 600V
- **Pickup:** Fixed

### Supporting documents:

- [Eatons Volume 4-Circuit Protection](#)
- [Eaton Specification Sheet - FG3015](#)

### Certifications:

- UL Listed
- UL 489
- CSA Certified
- CSA Std. C22.2 No. 5
- IEC Rated

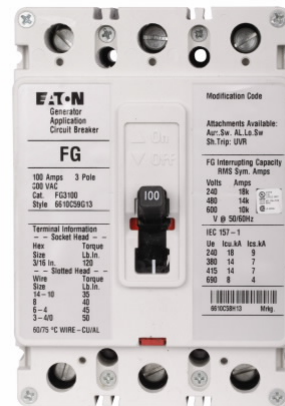

- IEC 947-2

**Product compliance:** No Data

---

© 2016 Eaton. All rights reserved.