



Powering Business Worldwide

pe.eaton.com

12 mm Screw connection single level-through-feed

XBUT16

UPC:782116905034

Dimensions:

- **Height:** X
- **Length:** .244 IN
- **Width:** X

Warranties:

- 1 year

Specifications:


- **Type:** IEC-XB Series
- **Amperage Rating:** IEC 41A, EN 30,38A, UL 30A
- **Color:** Gray
- **Maximum Wire Size:** 10 AWG/4 mm²
- **Voltage Rating:** IEC 800V, EN 700V, UL 600V
- **Wire Size:** IEC #26-10 AWG, EN #26-10 AWG, UL #26-10 AWG

Supporting documents:

- [Eatons Volume 7-Logic Control, Operator Interface and Connectivity Solutions](#)
- [XBUT16 AutoCAD 2D Footprint \(mm\)](#)
- [XB IEC terminal blocks-versatility, quality, and reliability](#)
- [XB IEC TERMINAL BLOCKS](#)
- [XBUT16 2D Drawing Xchange](#)
- [Eaton Specification Sheet - XBUT16](#)
- [XBUT16 2D PDF](#)
- [XBUT16 AutoCAD 2D Footprint](#)
- [XBUT16 3D Model Xchange](#)
- [XBUT16 3D Inventor](#)

Certifications:

- CSA Certified

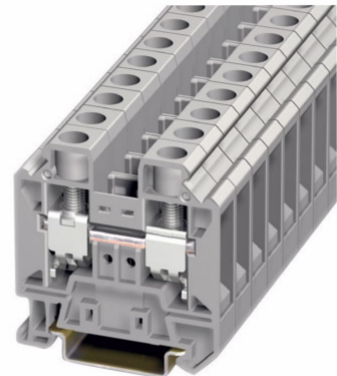

- UL Listed

Product compliance: No Data

© 2016 Eaton. All rights reserved.