



STARTER PKZ2



Powering Business Worldwide™

Part no.

PKZ2

Article no.

026606

Delivery programme

| | | | |
|-----------------------------|-------|---|--|
| Product range | | | PKZ2 basic unit up to 40 A - PRODUCT DISCONTINUATION IN 2012 |
| Basic function | | | Motor protection System protection |
| Rated uninterrupted current | I_u | A | 40 |
| Pole | | | 3 pole |

Approvals

Product Standards

UL File No.

UL CCN

CSA File No.

CSA Class No.

NA Certification

Specially designed for NA

UL 508; CSA-C22.2 No. 14; IEC60947-4-1; CE marking

E36332

NLRV

12528

3211-05


UL listed, CSA certified

No

Technical data ETIM 4.0

| | | | |
|---------------------------------------|--|-----|------------------|
| Rated operation power at AC-3, 400 V | | kWh | 20 |
| With integrated auxiliary switch | | | No |
| Rated permanent current I_u | | A | 40 |
| With integrated under voltage release | | | No |
| Number of poles | | | 3 |
| Degree of protection (IP) | | | IP00 |
| Connection type main current circuit | | | Screw connection |

Dimensions

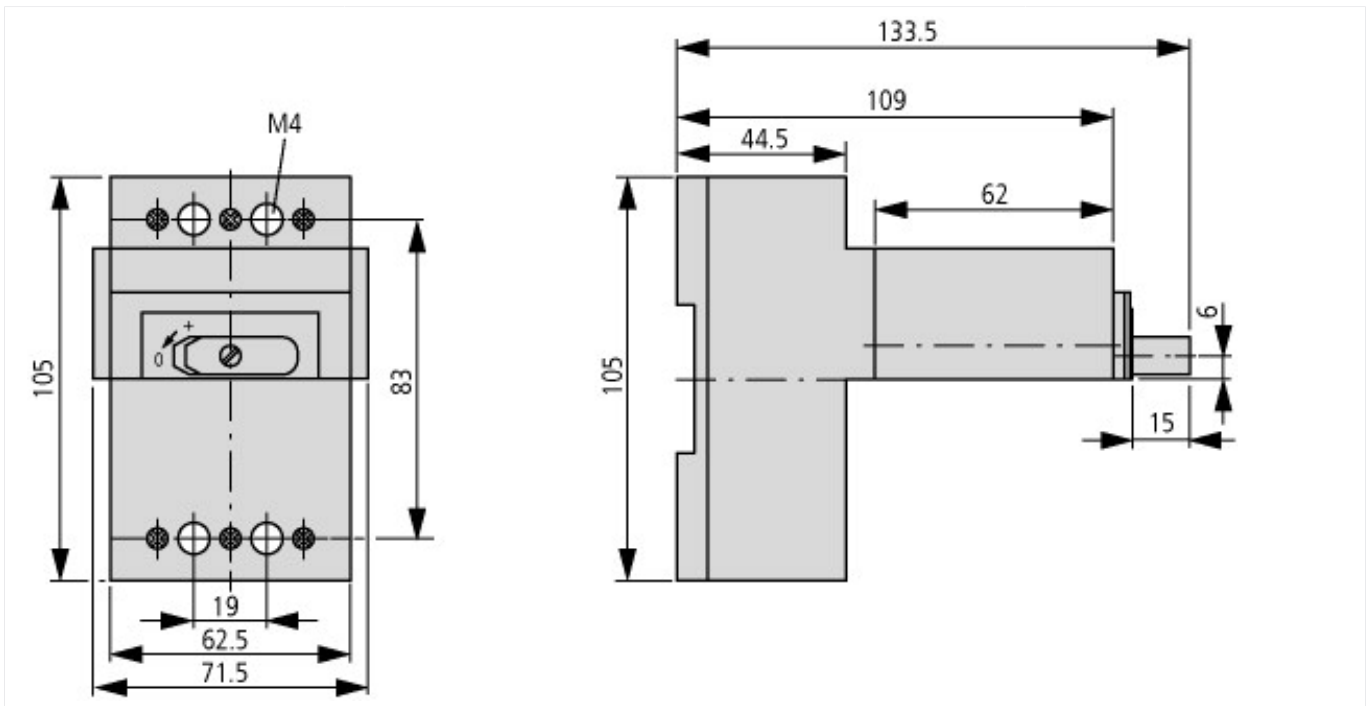

Additional product information (links)

AWA1280-0876 Motor-protective circuit-breaker

[AWA1280-0876 Motor-protective circuit-breaker](#)

AWB1210-1485 PKZ2 motor-protective circuit-breakers, overload monitoring of EEx e motors

[AWB1210-1485 PKZ2 motor-protective circuit-breakers, overload monitoring of EEx e motors](#)

Motor starters and "Special Purpose Ratings" for the North American market

http://www.moeller.net/binary/ver_techpapers/ver953en.pdf

