

Type _____

-31


P8652

P8653

P8654

P8655

Catalog No.	Finish	Wattage	Dimensions (Inches)		
	Black		A	B	C
P8652	-31	100	3-1/2	3-1/4	8-1/2
P8653	-31	150	4-1/8	3-3/4	8-1/2
P8654	-31	300	4-1/8	4-3/4	8-1/2
P8655	-31	600*	4-5/8	4-1/2	12

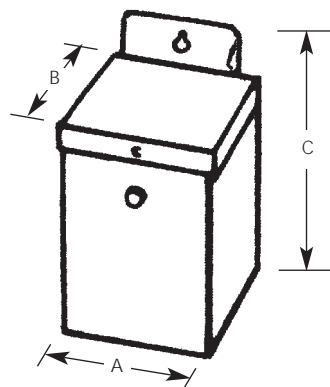

*2/300w circuits

Specifications:

Electrical

- Dual secondary taps of 12.0 and 12.6 volts
 - Maximizes light output and lamp life under varying load conditions
 - Adjusts for light loss in longer runs
- Isolation type transformer for safe operation
- Loads on P8655 two 300 watt circuits must be balanced for optimum operation
- Thermostat in primary to prevent overheating
- Resettable circuit breakers in secondary circuit to protect lighting components
- Induction type switches and dimmers only must be installed in the primary side

Construction

- Black powder coat finish on steel
- Epoxy encapsulated transformer for quiet and cool operation
- Easy open closure with KO's for hardwiring and installation

Mounting

- Horizontal or vertical mounting
- Top mounting bracket with keyhole slot is attached to housing
- Can be mounted anywhere indoors

Labeling

- UL-CUL listed