

PRODUCT QUICK SEARCH:

Penn Union Search:

Competitor Search:


Now In: [Penn-Union Products](#) → [Mechanical Lugs & Splices](#) → [Aluminum Terminal Lugs](#) → [RAA \(cable\) - Cable to Flat](#) → RAA-025-F - Aluminum Terminal



RAA-025-F - Aluminum Terminal

- Heavy Duty / Cable to Flat
- For aluminum and ACSR wire
- High strength electrical aluminum alloy
- Massive extra thick sections
- Conforming contact grooves
- Generous extra long contact lengths

Product Drawing:

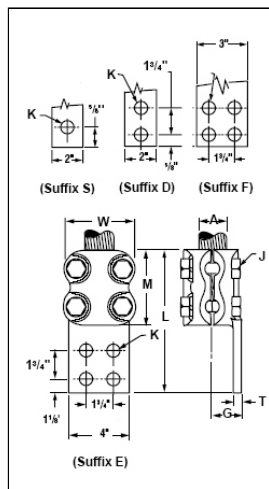

[Click to expand.](#)

Large size, high strength, anodized and lubricated 2024T4 aluminum alloy clamping hardware

Bolt heads pocketed for single wrench installation

Rounded contours

NEMA drilling supplied. Other drilling, or undrilled, available on request.

For copper flashed pad on tongue, add suffix "C" to the catalog designation. Example: RAAC-013-D

For tin plated terminal, add "-TN" to catalog number. Example: RAA-013-D-TN

For tongue mounting hardware, suffix catalog number with "-TMH". Example: RAA-013-D-TMH. (Aluminum hardware provided for type RAA, steel hardware for type RAAC)

Conductor Type	Conductor Range	Wire Diameter (in.)
Aluminum	6 Str. - 250 MCM	.184 - .575
ACSR	6 - 4/0	.184 - .575

No. of Holes in Pad: 4

Approximate Dimensions

G (in.):	7/8
J (in.):	1/2
K (in.):	9/16
L (in.):	6
M (in.):	2 3/4
T (in.):	3/8
W (in.):	2 1/8