

UL 489 Cable-In / Cable-Out Branch Circuit Breaker

QC Circuit Breakers

PRODUCT OVERVIEW


Type QC Miniature Circuit Breakers— Cable-In / Cable-Out Type QC

For Cable-In / Cable-Out Panel-Mount Applications

- Single-, two-, three- and four-pole options
- Built and listed to UL® 489
- All products UL and CSA® listed
- All products 10–100A are HACR rated



Type QC Miniature Circuit Breakers—Cable-In / Cable-Out Type QC—Catalog Numbering System

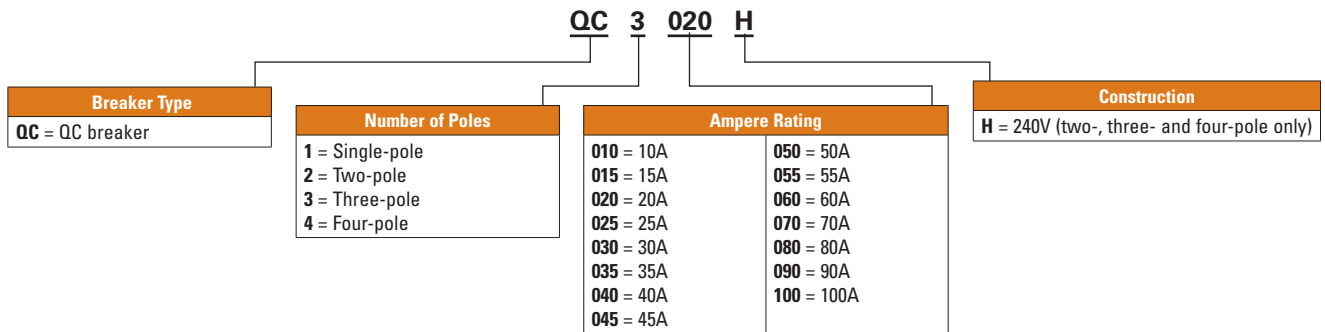

QUICKLAG® Type QC 10,000 Ampere Interrupting Capacity Thermal-Magnetic Breakers

Continuous Ampere Rating at 40°C	Single-Pole 120/240 Vac Catalog Number	Two-Pole 120/240 Vac Catalog Number	Three-Pole 240 Vac Catalog Number
10	QC1010	QC2010	—
15	QC1015 ① ②	QC2015	QC3015H
20	QC1020 ① ②	QC2020	QC3020H
30	QC1030	QC2030	QC3030H
40	QC1040	QC2040	QC3040H
50	QC1050	QC2050	QC3050H
60	—	QC2060	QC3060H
70	—	QC2070	QC3070H
100	QC1100	QC2100	QC3100H

① Switching duty rated for 120 Vac fluorescent light applications only.

② For special low-magnetic breaker, order QC1015L1 or QC1020L1.

Note: For non-automatic switches, see catalog Volume 4: Circuit Protection, CA08100005E, Tab 24.