

**Manual Motor Protectors**

**Pushbutton MMP Enclosures**



**B-Frame**

**B**

**Table B-156. Insulated Enclosures for Surface Mounting of XTPB Pushbutton Motor-Protective Circuit Breakers — Global Usage ①**

	Degree of Protection	For Use with...	Description	Catalogue Number	Price	Approx. Dimensions mm [in] H x W x D
	IP40 NEMA 1	XTPB MMP Only or with: XTPAXFA..., XTPBXFAEM20, XTPAXSA..., XTPAXUVR..., XTPAXSR...	—	<b>XTPBXENCS40</b>		158 x 80 x 116.5 [6.22 x 3.15 x 4.59]
	IP65 NEMA 3R, 4X, 12, 13		With actuation membrane.	<b>XTPBXENCS65</b>		158 x 80 x 116.5 [6.22 x 3.15 x 4.59]
	IP65 NEMA 3R, 4X, 12, 13	XTPB MMP Only or with: XTPAXFA..., XTPAXUVR..., XTPAXSR..., XTPAXCL	Lockable in OFF position.	<b>XTPBXENCSLO65</b>		158 x 80 x 129.5 [6.22 x 3.15 x 5.10]
	IP65 NEMA 3R, 4X, 12, 13	XTPB MMP Only or with: XTPAXFA..., XTPBXFAEM20, XTPAXUVR..., XTPAXSR..., XTPAXCL	Lockable in OFF position in combination with XTPBXFAEM20 Early Make front mount auxiliary contact	<b>XTPBXENCSLE65</b>		158 x 80 x 129.5 [6.22 x 3.15 x 5.10]
	IP65 NEMA 3R, 4X, 12, 13		With Emergency-Stop (E-Stop) pushbutton actuator, Red-Yellow	<b>XTPBXENCSES65</b>		158 x 80 x 177.2 [6.22 x 3.15 x 6.98]
	IP65 NEMA 3R, 4X, 12, 13		With Emergency-Stop (E-Stop) pushbutton actuator, Red-Yellow key release	<b>XTPBXENCSEK65</b>		158 x 80 x 177.2 [6.22 x 3.15 x 6.98]


① Integrated terminal for PE(N) connection, two M25 cable entry knockouts at top and at bottom.

**Table B-157. Insulated Enclosures for Surface Mounting of XTPB Pushbutton Manual Motor Protectors — North American Usage ②③**


	Degree of Protection	For Use with...	Description	Catalogue Number	Price	Approx. Dimensions mm [in] H x W x D
	IP41 NEMA 1	XTPB MMP Only or with: XTPAXFA..., XTPBXFAEM20, XTPAXSA..., XTPAXUVR..., XTPAXSR..., XTPAXCL	—	<b>XTPBXENAS41</b>		158 x 80 x 116.5 [6.22 x 3.15 x 4.59]
	IP65 NEMA 3R, 4X, 12, 13		With actuating diaphragm	<b>XTPBXENAS65</b>		158 x 80 x 116.5 [6.22 x 3.15 x 4.59]
	IP65 NEMA 3R, 4X, 12, 13	XTPB MMP Only or with: XTPAXFA..., XTPAXUVR..., XTPAXSR..., XTPAXCL	Lockable in OFF position	<b>XTPBXENASLO65</b>		158 x 80 x 129.5 [6.22 x 3.15 x 5.10]
	IP65 NEMA 3R, 4X, 12, 13	XTPB MMP Only or with: XTPAXFA..., XTPBXFAEM20, XTPAXUVR..., XTPAXSR..., XTPAXCL	Lockable in OFF position in combination with XTPBXFAEM20 Early Make front mount auxiliary contact.	<b>XTPBXENASLE65</b>		158 x 80 x 129.5 [6.22 x 3.15 x 5.10]
	IP65 NEMA 3R, 4X, 12, 13		With Emergency-Stop (E-Stop) pushbutton actuator, Red-Yellow	<b>XTPBXENASES65</b>		158 x 80 x 177.2 [6.22 x 3.15 x 6.98]
	IP65 NEMA 3R, 4X, 12, 13		With Emergency-Stop (E-Stop) pushbutton actuator, Red-Yellow key release	<b>XTPBXENASEK65</b>		158 x 80 x 177.2 [6.22 x 3.15 x 6.98]

② Built-in terminal for PE(N).

③ North American enclosures come with conduit adapters for use with 1/2" NPT.

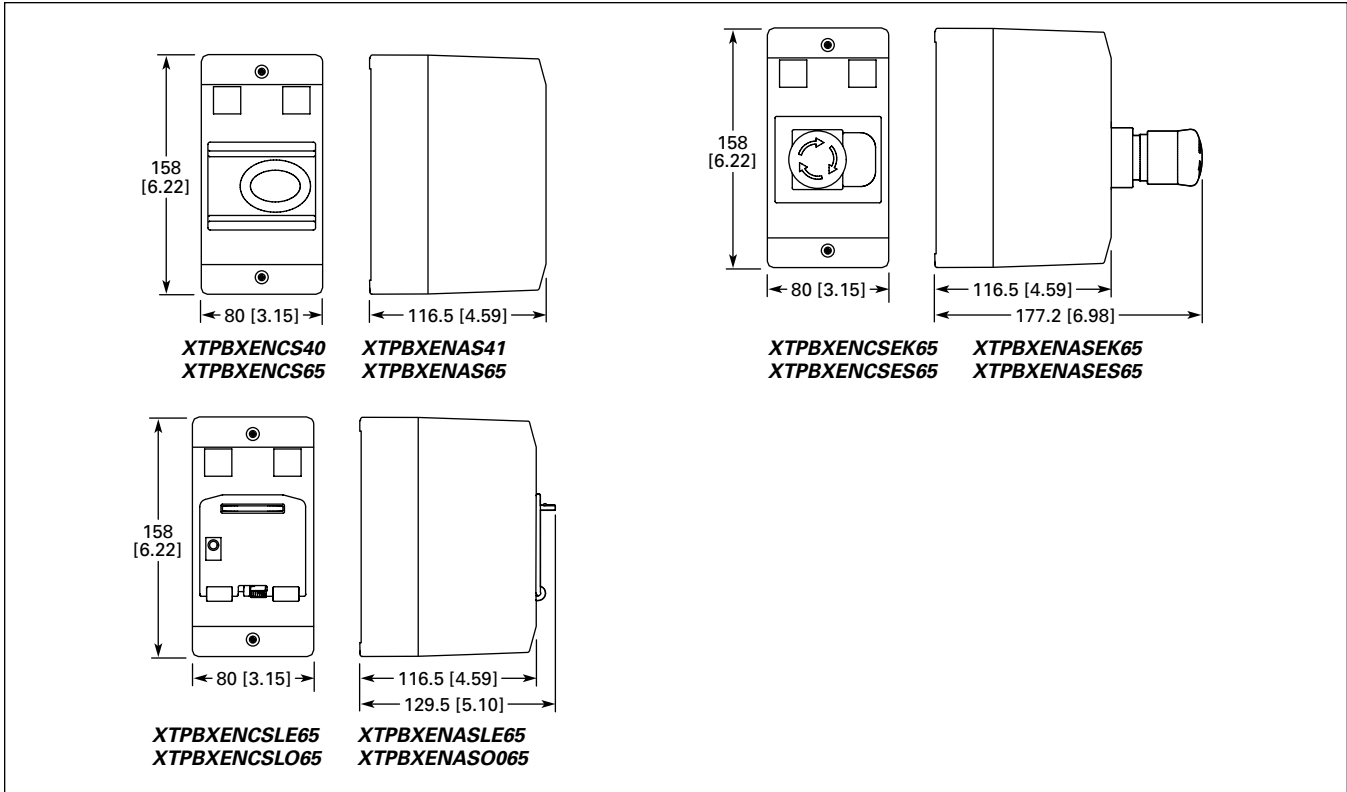

**Figure B-119. Insulated Enclosures for Surface Mounting of XTPB Manual Motor Protectors (Approximate Dimensions in mm [in])**

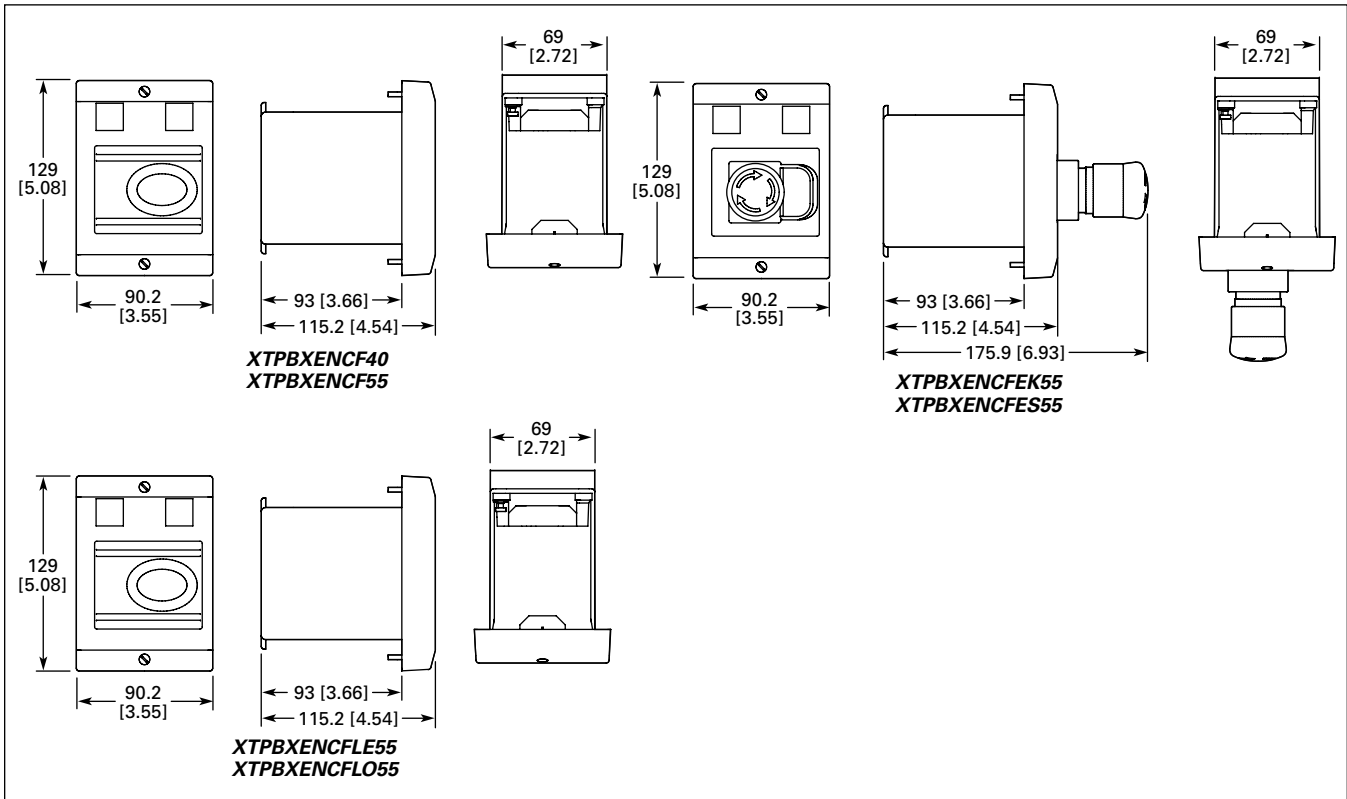

**Figure B-120. Insulated Enclosures for Flush Mounting of XTPB Manual Motor Protectors (Approximate Dimensions in mm [in])**