



Powering Business Worldwide

[pe.eaton.com](http://pe.eaton.com)

## HMI-PLC XV Operator Interface

XV-102-E8-70TWRC-10

### Dimensions:

- **Height:** 3.5 IN
- **Length:** 11 IN
- **Width:** 7.5 IN

**Weight:** 2 LB

**Notes:** All 1xx performance class units have 400MHz processor, 64 MB DRAM, 1x10/100 Ethernet, and 1x USB device.

### Warranties:

- Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

### Specifications:


- **Base Unit:** Retentive memory, USB host, SmartWire-DT
- **Bezel:** Standard blank front bezel
- **Class:** Second generation CE plastic housing
- **Communication:** PROFIBUS
- **Display:** 7.0 in TFT resistive touch (widescreen)
- **Operating System:** XSoft-CoDeSys/Galileo

### Supporting documents:

- [Eatons Volume 7-Logic Control, Operator Interface and Connectivity Solutions](#)
- [XV and XP Series Operator Interfaces Product Aid - PA04801003E](#)
- [Eaton Specification Sheet - XV-102-E8-70TWRC-10](#)

### Certifications:

- UL Listed
- cULus Listed

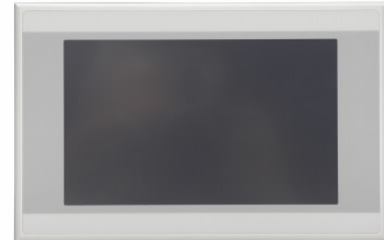

**Product compliance:**

- RoHS Compliant
- CE Marked

---

© 2016 Eaton. All rights reserved.