




Flexible Steel Conduit

TYPE - VJC



[Contact your local Sales Representative](#)
[Click Here for Printable Version](#)

			Inside Diameter	Outside Diameter Over Jacket	Internal Bend Radius		Carton		List Price
Type	U.S. Electrical Trade Size	Metric Trade Size	Min / Max	Min / Max	Static / Dynamic	Wt. (Lbs.)/ 100 Ft.	Length	Part #	Price Per 100 FT
VJC-10	3/8"	16mm	0.492 / 0.516	0.657 / 0.681	1.0" / 5.0"	14	100	89201	\$48.00
VJC-11	1/2"	-	0.622 / 0.646	0.799 / 0.823	1.0" / 6.0"	16	100	89211	\$67.00
VJC-12	3/4"	25mm	0.815 / 0.839	0.996 / 1.020	2.0" / 8.0"	20	100	89221	\$90.00
VJC-13	1"	-	1.043 / 1.067	1.240 / 1.264	3.0" / 10.0"	35	100	89232	\$104.00
VJC-14	1-1/4"	-	1.378 / 1.402	1.642 / 1.673	3.0" / 12"	38	50	89242	\$168.00
VJC-15	1-1/2"	-	1.575 / 1.598	1.850 / 1.890	3.5" / 14"	44	50	89252	\$213.00
VJC-16	2"	-	2.008 / 2.031	2.307 / 2.346	4.0" / 16"	66	50	89262	\$317.00
VJC-18	3"	-	3.071 / 3.094	3.425 / 3.465	6.5" / 25"	93	25	89282	\$857.00

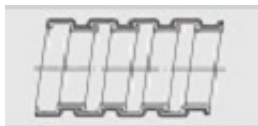

For RoHS and WEEE compliance, please consult factory.

TYPE - VJC

Vacuum jacketed non-UL steel conduit for high-flex installations.

CONSTRUCTION:

A unique vacuum extrusion process allows this product to have a thin PVC jacket which does not restrict the great flexibility characteristics of the inner core. The core material is the same as Type SL and is made from zinc plated (galvanized) steel. VJC is designed with dimensions that will accept standard liquidtight connectors.

APPLICATION:

VJC is suitable for use in both static applications where a tight bend diameter is needed and in dynamic use such as machining centers and robotics.

STANDARD COLORS:

Black. [Other colors available upon request](#)

WORKING TEMPERATURES:

-20°C to 80°C

Flexibility: [See the Flexibility Comparison Guide](#)

Metal Used: Steel

Plastic Used: PVC [See the Chemical Resistance Guide](#)

High Mech. Strength	Listed For Direct Burial	Halogen Free	Low Fire Hazard	Accepts Standard Liquidtight Fittings	Self Extinguish	EMI/RFI Shielding	Oil Resistance	Acid Resistance
---------------------	--------------------------	--------------	-----------------	---------------------------------------	-----------------	-------------------	----------------	-----------------

				X			X	X
--	--	--	--	---	--	--	---	---

[Packaging, Disclaimer and Warranty](#)

® Electri-Flex Company 1-800-323-6174

[Privacy](#) [Terms](#)