

Applications: **AS** **IC**

**B36RIC**

**6" SLOPE IC REMODEL HOUSING**

2/12 to 6/12 Pitch (9° to 27°)

6" SLOPE IC REMODEL HOUSING



6"		
B36RIC • B392CL 75W PAR30 FL		
4'	131	2.5'
6'	60	3.8'
8'	33	5.0'
10'	21	6.3'
12'	15	7.6'
14'	11	8.8'
Distance to Plane	Initial Nadir Footcandles	Beam Spread

Data Certified by ATC  
BEAM DIA. MEASURED AT 50% OF NADIR F.C.

**DESCRIPTION:**

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. Designed for sloped ceiling applications where the ceiling pitch ranges from 2/12 to 6/12. Accommodates up to 75W PAR30, R30 lamps, 60W A19 lamps and 65W BR30 lamps. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KO's and four Romex knockouts with strain relief.

**Lamp Wattage:**

(1) Maximum 75W R/PAR30, 60W A19, 65W BR30



**FEATURES:**




- Thermally Protected IC Remodel Housing.
- The socket bracket is specially designed to swivel and rotate so the lamp could be aligned properly. The lamp will aim straight down regardless of the ceiling pitch.
- Adjustable socket bracket with a slope indicator provides consistent lamp alignment and setup.
- Unit slips through 6-1/2" ceiling opening.
- Four Preinstalled spring clips which secure the housing firmly into ceiling and accommodate different ceiling thicknesses from 1/2" to 1-3/8".
- Wire through junction box.
- Can be installed from below the ceiling.
- Dependable, favorable design and effortless installation.
- 7 1/2" height allows use in 2"x 8" joist construction.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

**SPECIFICATION:**

- A. HOUSING** - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.
- B. SOCKET** - Medium base screw shell porcelain socket preinstalled on a mounting bracket is specially designed to swivel and rotate so the lamp could be aligned properly. The lamp will aim straight down regardless of the ceiling pitch.
- C. INSTALLATION** - Four Preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".
- D. JUNCTION BOX** - ETL listed for through-branch circuit wiring and has eight 1/2" KO's and four Romex knockouts with strain relief.
- E. THERMAL PROTECTION** - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

**OPTION:**

- 1. AIR-SHUT-**
  - Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

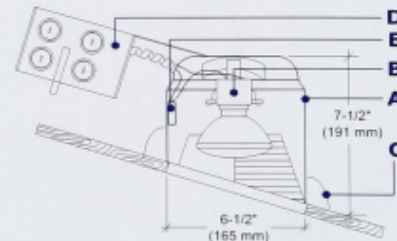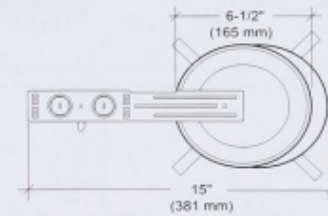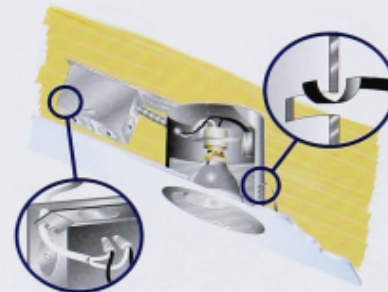

**ETL and C-ETL listed**

For Damp location  
For Feed-through wiring  
For Direct contact with insulation

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	OPTION
<input type="checkbox"/> B36RIC	<input type="checkbox"/> AT = AIR SHUT



INCANDESCENT