

# B5RIC

## 5" Universal IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30

Catalog Number:

Project Name:

Type:

Note:



DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

### DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with a strain relief. Accommodates up to 75W PAR30, R30 lamps, 60W A19 lamps and 65W BR30 lamps.

### SPECIFICATION


**A. HOUSING** - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

**B. SOCKET** - Medium base screw shell porcelain socket snaps into trim to allow usage of different lamp types, as well as proper and consistent lamp positioning.

**C. INSTALLATION** - Four Preinstalled spring clips which secure the housing firmly into ceiling and accommodate ceiling thickness from 1/2" to 1-3/8".

**D. JUNCTION BOX** - UL and ETL listed for feed through wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

**E. THERMAL PROTECTION** - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

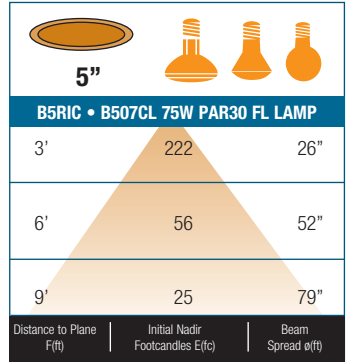

### FEATURES

- Thermally Protected IC Remodel housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 5-1/2" ceiling opening.
- Four Preinstalled spring clips which secure the housing firmly into ceiling to accommodate ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 7" height allows use in 2" x 8" joist construction.
- Wire through junction box.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.


### OPTIONS

#### AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

#### UL AND C-UL/ETL AND C-ETL LISTED

- For Damp location
- For Feed-through wiring
- For Direct contact with insulation

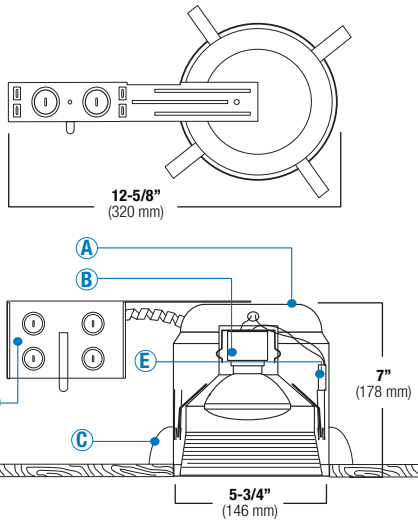

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE	BAFFLE	REFLECTOR	TRIM/RING	GLASS	
B5RIC	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B530 <input type="checkbox"/> B507 <input type="checkbox"/> B563 <input type="checkbox"/> B502 <input type="checkbox"/> B520 <input type="checkbox"/> B573 <input type="checkbox"/> B504 <input type="checkbox"/> B501 <input type="checkbox"/> B505 <input type="checkbox"/> B535 <input type="checkbox"/> B536	<input type="checkbox"/> B541 <input type="checkbox"/> B542 <input type="checkbox"/> B504L <input type="checkbox"/> B501L <input type="checkbox"/> B505L	<input type="checkbox"/> W <input type="checkbox"/> P <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> BZ	<input type="checkbox"/> CL <input type="checkbox"/> RG <input type="checkbox"/> W <input type="checkbox"/> MB <input type="checkbox"/> BZ <input type="checkbox"/> CP <input type="checkbox"/> SN <input type="checkbox"/> SHZ	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> CH <input type="checkbox"/> PB <input type="checkbox"/> BZ	<input type="checkbox"/> Green <input type="checkbox"/> Yellow <input type="checkbox"/> Pink <input type="checkbox"/> Brown <input type="checkbox"/> Navy Blue <input type="checkbox"/> Orange <input type="checkbox"/> Blue <input type="checkbox"/> White <input type="checkbox"/> Red

### Specifications:

B5RIC

AIR-SHUT    OPTION    TRIM TYPE    BAFFLE    REFLECTOR    TRIM/RING    GLASS

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

Sample of Catalog Number: B5RIC-AT-W-B530-W-WH

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

# 5" Incandescent Trims

(LAMP WATTAGE: 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:


Note:



**B530CP-CP  
STEPPED BAFFLE**




**AVAILABLE COLOR COMBINATIONS:**  
CP-CP, SN-SN, W-WH, P-WH, P-BK, BZ-BZ

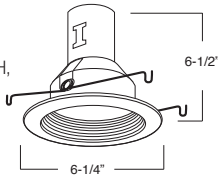


**B507RG-WH  
REFLECTOR**




**AVAILABLE COLOR COMBINATIONS:**  
CP-CP, W-WH, RG-WH, MB-WH, CL-WH, MB-BK, RG-PB, CL-CH

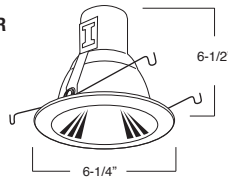

**B563PB  
PAR30 GIMBAL TRIM**

 


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

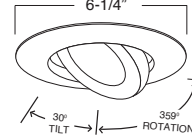

**B502SN  
EYEBALL**




**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH, PB, BZ

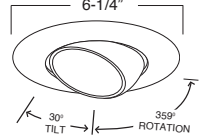

**B520-NAVY BLUE  
GLASS TRIM**




**GLASS FINISH:**  
GREEN, YELLOW, PINK, BROWN, NAVY BLUE, ORANGE, WHITE, RED

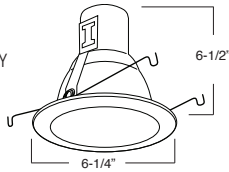

**B573W-WH  
PAR30 BAFFLE W/ GIMBAL RING**



**AVAILABLE COLOR COMBINATIONS:**  
CP-CP, SN-SN, W-WH, P-WH, P-BK

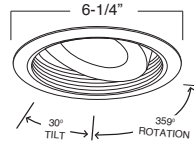


**B504WH  
SHOWER TRIM**



FOR WET LOCATION

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH, BZ

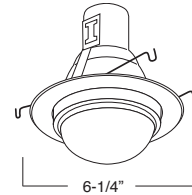


**B501CP  
METAL ALBALITE LENS**



FOR WET LOCATION

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH, BZ

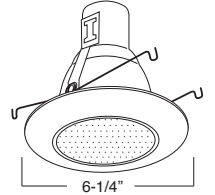


**B505SN  
METAL FRESNEL LENS**



FOR WET LOCATION

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH, BZ

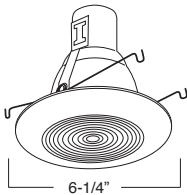


**B535P-WH  
BAFFLE WITH ALBALITE LENS**



FOR WET LOCATION

 **AVAILABLE COLOR COMBINATIONS:**  
CP-CP, SN-SN, W-WH, P-WH, P-BK




**B536W-WH  
BAFFLE WITH FRESNEL LENS**



FOR WET LOCATION

 **AVAILABLE COLOR COMBINATIONS:**  
CP-CP, SN-SN, W-WH, P-WH, P-BK




**B541RG-WH  
REFLECTOR WITH ALBALITE LENS**



FOR WET LOCATION

 **AVAILABLE COLOR COMBINATIONS:**  
CP-CP, W-WH, RG-WH, MB-BK, CL-WH, MB-BK, RG-PB, CL-CH




**B542CL-WH  
REFLECTOR WITH FRESNEL LENS**



FOR WET LOCATION

 **AVAILABLE COLOR COMBINATIONS:**  
CP-CP, W-WH, RG-WH, MB-BK, CL-WH, MB-BK, RG-PB, CL-CH




**B504L  
PLASTIC SHOWER TRIM**



FOR WET LOCATION

**TRIM/RING FINISH:**  
WHITE PLASTIC

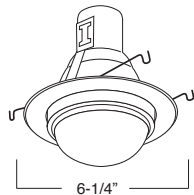


**B501L  
PLASTIC ALBALITE LENS**



FOR WET LOCATION

**TRIM/RING FINISH:**  
WHITE PLASTIC

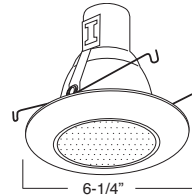

**B505L  
PLASTIC FRESNEL LENS**



FOR WET LOCATION

**TRIM/RING FINISH:**  
WHITE PLASTIC

