


STEP LIGHT

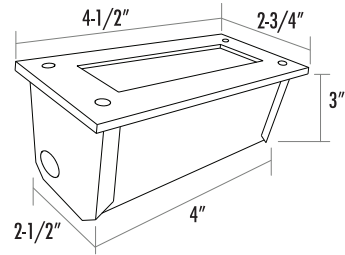

SEI06-LED-WH

Diffuse Glass Lens
w/White Trim

Housing Included

COVER FINISH

WH-White BR-Bronze SN- Satin Nickel

LED LAMP COLOR

WW-Warm White AM- Amber

SEI07-LED-WH

Angled Louvers
w/White Trim

Housing Included

- 0.4 W (0.05W X 8)
- 120V input
- For use indoors in insulated (IC) and Non-insulated (NON-IC) areas.
- For damp location only.
- Conforms to UL standard I598.

SEI05-LED-WH

Diffuse Glass Lens w/ White Trim Housing Included.
Trim size: L=9-1/2" X H=4-7/8"

FINISH

WH-White BR-Bronze SN- Satin Nickel




SE84 I-LED-WH

Angled Louvers w/ White Trim Housing Included.
Trim size: L=9-1/2" X H=4-7/8"

FINISH

WH-White BR-Bronze SN- Satin Nickel

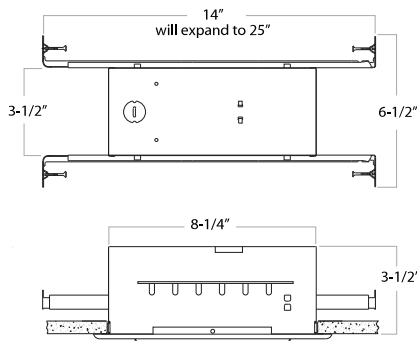

FINISH:

WH-White
BR-Bronze
SN- Satin Nickel

- 0.9W (0.05X18)
- 120V input
- For use indoors in insulated (IC) and Non-insulated (NON-IC) areas.
- For damp location only.
- Conforms to UL standard I598.