

5109IND

WEATHERPROOF

- Survives rugged weather on the job
- Floats for easy recovery



BRIGHT

- Large reflector provides better illumination



DURABLE

- Shatterproof lens
- Polyethylene case resists damage from dropping or abuse



AMERICAN MADE

- Great for contracts requiring "Buy American"



A great choice for wet areas and outdoor work, the 5109IND is weatherproof and floats for easy recovery from water. It stays where you put it and provides a large lit area, making it a terrific area light.

A shatterproof lens and a rugged polyethylene case help it stand up to rough job site conditions. Made in the USA, it is an ideal light for municipal contracts requiring Buy American.




Before Using Your Flashlight:
Please read all instructions and cautionary markings on the package and light

Product Detail:

Designation:	Industrial 6V Economy Lantern
Model:	5109IND
Color:	Yellow
Power Source:	6V Alkaline Spring Terminal Battery
ANSI/NEDA:	908AC Series
Lamp:	PR-13
Lamp Rating:	4.75V, 0.5A
Lamp Life:	15 Hours
Lamp Output:	28.5 Lumens
Typical Weight:	220 grams (7.7 oz.) (without battery)
Dimensions (in):	7.15 x 4.57 x 4.57

Performance:

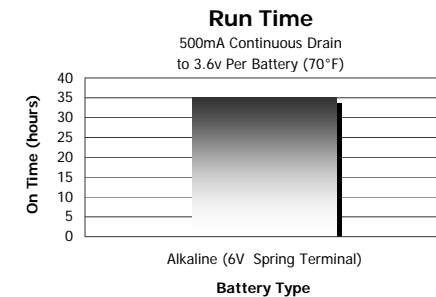

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication

Contents herein do not constitute a warranty
©Energizer / All Rights Reserved