



# TUFHD31PH

The TUFHD31P is built to take tough conditions on the job while providing a dependable hands-free lighting solution. Four lighting modes are controlled by two easy to operate push button switches. The light pivots to direct the beam where you need it; and the comfortable, adjustable head band stays where you put it, whether on your head or on a hard hat.



## VERSATILE

- Four lighting modes - high and low white beam, red for night vision, green for pipe inspection
- Flip up lens diffuses spot to area light



## DURABLE

- Survives 15 foot drop test



## COMFORTABLE

- Rear mount battery pack distributes weight evenly
- Battery pack and light are cushioned



## SECURE


- Non-slip strap stays put on hard hat or head
- Features removable top strap



## Product Detail:

- Designation:** Hard Case Professional Headlight  
**Model:** TUFHD31PH  
**Color:** Black and Gray  
**Power Source:** Three "AA"  
**ANSI/NEDA:** 15 Series  
**Lamp:** White CREE XRE LED  
**White LED Output:** 100 Lumens  
**Additional Lamps:** 2 Red and 1 Green LED  
**Typical Weight:** 201.50 grams (7.12 oz.) (with alkaline batteries)  
**Dimensions (in.):** Light - 3.12 x 2.12 x 1.13  
 Battery Pack - 3.00 x 2.75 x 1.13

## Performance:

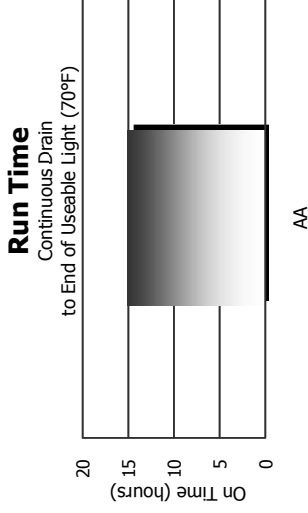

**Important Notice**  
 This datasheet contains information specific to products manufactured at the time of its publication  
**Contents herein do not constitute a warranty**  
 ©Energizer / All Rights Reserved

**Before Using Your Flashlight:**  
 Please read all instructions and cautionary markings on the package and light

