
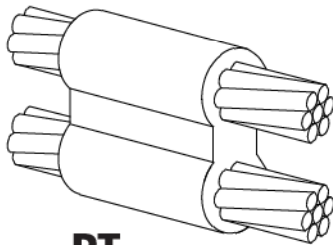


PG

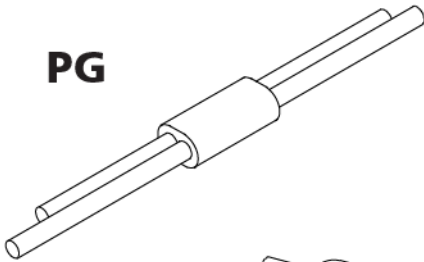

PT

PARALLEL HORIZONTAL CONDUCTORS

- Parallel through connection of horizontal cables.
- Run conductor is on the bottom of Type PT molds.
- Concentric stranded copper cable unless otherwise noted.
- Solid conductor may be either copper or Copperweld®.
- **Bold letter** in mold part number is the price key.

REQUIRED TOOLS

Handle Clamps **L160** for **C** Price Key Molds

Clamps are included with T Price Key Molds

Flint Ignitor **T320** (Included with Handle Clamp or frame but also available separately)

SUGGESTED TOOLS

Cable Cleaning Brush	T313 or T314
Slag Removal Spade	B136A or B136B
Mold Cleaning Brush	T394
Cable Clamp	B265
Torch Head	T111

ACCESSORIES

See Section A


CABLE SIZE		MOLD PART NO.	WELD METAL	
Run	Tap			
6 SOL	6 SOL	PGT-1G1G	25	
6	6	PGT-1H1H	25	
4	4	PTC-1L1L	32	
	6	PTC-1L1H	32	
	6 SOL	PTC-1L1G	32	
	8	PTC-1L1E	32	
	8 SOL	PTC-1L1D	32	
2 SOL	2	PTC-1T1V	65	
	2 SOL	PTC-1T1T	65	
	4	PTC-1T1L	65	
	6	PTC-1T1H	45	
	6 SOL	PTC-1T1G	45	
	8	PTC-1T1E	45	
	8 SOL	PTC-1T1D	45	
	2	2	PTC-1V1V	65
		4	PTC-1V1L	65
6		PTC-1V1H	45	
6 SOL		PTC-1V1G	45	
8		PTC-1V1E	45	
8 SOL		PTC-1V1D	45	
1 SOL		1	PTC-1X1Y	65
		2	PTC-1X1V	65
	2 SOL	PTC-1X1T	65	
	4	PTC-1X1L	65	
	6	PTC-1X1H	65	
	6 SOL	PTC-1X1G	65	
	8	PTC-1X1E	45	
	8 SOL	PTC-1X1D	45	

CABLE SIZE		MOLD PART NO.	WELD METAL
Run	Tap		
1	1	PTC-1Y1Y	65
	1 SOL	PTC-1Y1X	65
	2	PTC-1Y1V	65
	2 SOL	PTC-1Y1T	65
	4	PTC-1Y1L	65
	6	PTC-1Y1H	65
	6 SOL	PTC-1Y1G	65
	8	PTC-1Y1E	45
	8 SOL	PTC-1Y1D	45
	1/0 SOL	1/0	PTC-2B2C
1/0 SOL		PTC-2B2B	90
1		PTC-2B1Y	65
1 SOL		PTC-2B1X	65
2		PTC-2B1V	65
2 SOL		PTC-2B1T	65
4		PTC-2B1L	65
6		PTC-2B1H	65
6 SOL		PTC-2B1G	65
8		PTC-2B1E	65
8 SOL		PTC-2B1D	65



CABLE SIZE		MOLD PART NO.	WELD METAL
Run	Tap		
1/0	1/0	PTC-2C2C	90
	1/0 SOL	PTC-2C2B	90
	1	PTC-2C1Y	65
	1 SOL	PTC-2C1T	65
	2	PTC-2C1V	65
	2 SOL	PTC-2C1T	65
	4	PTC-2C1L	65
	6	PTC-2C1H	65
	6 SOL	PTC-2C1G	65
	8	PTC-2C1E	65
	8 SOL	PTC-2C1D	65
	2/0	2/0	PTC-2G2G
1/0		PTC-2G2C	115
1/0 SOL		PTC-2G2B	115
2		PTC-2G1V	90
1		PTC-2G1Y	90
1 SOL		PTC-2G1X	90
4		PTC-2G1L	90
6		PTC-2G1H	90
6 SOL		PTC-2G1G	90
8		PTC-2G1E	65
8 SOL		PTC-2G1D	65
3/0		3/0	PTC-2L2L
	2/0	PTC-2L2G	150
	1/0	PTC-2L2C	115
	1/0 SOL	PTC-2L2B	115
	2	PTC-2L1V	115
	2 SOL	PTC-2L1T	115
	1 SOL	PTC-2L1X	115
	1	PTC-2L1Y	115
	4	PTC-2L1L	115
	6	PTC-2L1H	90
	6 SOL	PTC-2L1G	90
	8	PTC-2L1E	90
8 SOL	PTC-2L1D	90	

CABLE SIZE		MOLD PART NO.	WELD METAL
Run	Tap		
4/0 SOL	4/0	PTC-2P2Q	200
	4/0 SOL	PTC-2P2P	200
	3/0	PTC-2P2L	200
	2/0	PTC-2P2G	150
	1/0	PTC-2P2C	150
	1/0 SOL	PTC-2P2B	150
	1	PTC-2P1Y	150
	1 SOL	PTC-2P1X	150
	2	PTC-2P1V	150
	2 SOL	PTC-2P1T	150
	4	PTC-2P1L	150
	6	PTC-2P1H	90
4/0	6 SOL	PTC-2P1G	90
	8	PTC-2P1E	90
	8 SOL	PTC-2P1D	90
	4/0	PTC-2Q2Q	200
	4/0 SOL	PTC-2Q2P	200
	3/0	PTC-2Q2L	200
	2/0	PTC-2Q2G	150
	1/0	PTC-2Q2C	150
	1/0 SOL	PTC-2Q2B	150
	1	PTC-2Q1V	150
	1 SOL	PTC-2Q1X	150
	2	PTC-2Q1V	150
2 SOL	PTC-2Q1T	150	
4	PTC-2Q1L	150	
6	PTC-2Q1H	90	
6 SOL	PTC-2Q1G	90	
8	PTC-2Q1E	90	
8 SOL	PTC-2Q1D	90	

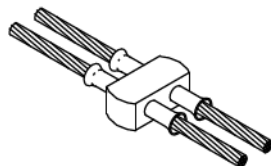

CONDUCTOR SIZE		ONE-SHOT Part No.
Solid	Stranded	Parallel Tap
3, 4	4, 6	PG11L

The CADWELD ONE-SHOT case is a ceramic disposable body replacing the familiar semi-permanent graphite mold and associated handle clamp. Everything required is included except the flint ignitor.

NEC Compliant, UL Listed