


**MOLD FASTENING AND MOUNTING (cont.)**

**Magnetic Handle Clamps**

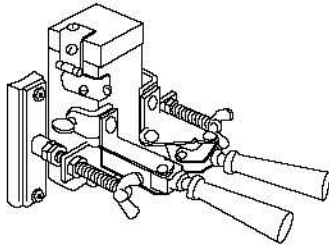


The CADWELD mold can be securely held to a large flat or slightly curved vertical surface using the Handle Clamp with Magnetic Support. Used on vertically split molds.

Clamp Part No.	Fits Mold Price Key	Minimum Width Required*
B396	C & R Price Key	8"
B159M	D & F Price Key	10-1/2"
B399AM	T Price Key	6"
B399BM	P & N Price Key	7"

\*Width will vary slightly depending upon the type of connection being made.

**Fence Fabric Attachment Assembly**

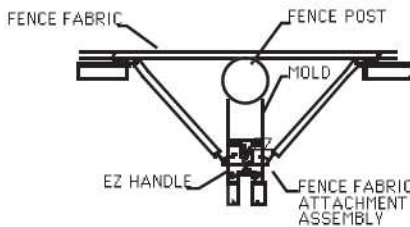

An easy to use, labor saving, Fence Fabric Attachment Assembly fastens to your existing L159 or L160 Handle Clamp to firmly hold your mold to the fence post after the fence fabric has been attached. Ideal for retrofit jobs.

Part No.	Fits Handles
B827A	L160, L159

**GROUND ROD SPECIALTY TOOLS**



 
**ERITECH® Ground Rod Drivers**

Product No.	Description
EGRD58	5' driver body with insert for up to 5/8" ground rods
EGRD58I*	Replacement insert for 5/8" ground rods
EGRD34	5' driver body with insert for up to 3/4" ground rods
EGRD34I*	Replacement insert for 3/4" ground rods

\*Both 5/8" and 3/4" inserts fit standard body of EGRD58 or EGRD34.

**Ground Rod Driving Sleeves\*\***

Use a CADWELD ground rod driving sleeve to prevent mushrooming the top of the ground rod.



Ground Rod Size	Part No.
1/2" Copperbonded or Steel Rod	B137-14
5/8" Copperbonded (.563" diameter)	B137-16
5/8" Steel (.625" diameter)	B137-31
3/4" Copperbonded (.682" diameter)	B137-18
3/4" Steel (.750" diameter)	B137-33
1" Copperbonded (.914" diameter)	B137-22
1" Steel (1.00" diameter)	B137-37

\*\* For plain (unthreaded) ground rods only.