

# Ground System Components


## Grounding Clamps and Connectors

### ERITECH Ground Clamps

- For use with copperbonded ground rods.
- Suitable for direct burial.


#### Bronze Standard Duty

Part No.	Conductor Range	Rod Size
CP38	10 Sol.- 4 Str.	3/8
CP12	8 Sol.- 2 Str.	1/2
CP58	8 Sol.- 2 Str.	5/8
CP34	8 Sol.- 2 Str.	3/4

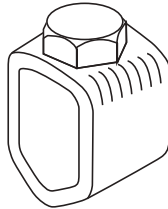

#### Bronze Heavy Duty


Part No.	Conductor Range	Rod Size
HDC12*	10 Sol.- 2 Str.	1/2
HDC58R*	8 Sol.- 1/0 Str.	5/8
HDC58*	8 Sol.- 1/0 Str.	5/8
HDC34*	8 Sol.- 1/0 Str.	3/4
HDC34SP	8 Sol.- 3/0 Str.	3/4
HDC1	1 Sol.- 4/0 Str.	1

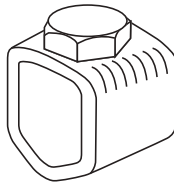

\*UL Listed


#### Galvanized Steel Clamps

Part No.	Rod Size
S58	1/2" rod #8 - 3/0 wire 5/8" rod #14 - 1/0 wire
S68	5/8" rod #14 - 16 wire 3/4" rod - 4/0 wire

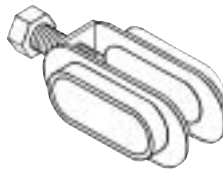

### ERITECH Split Bolts - Silicon Bronze

Part No.	Wire Range
ESB8	10 sol - 8 str.
ESB6	8 sol - 6 sol.
ESB4	8 sol - 4 sol.
ESB3	6 sol - 3 str.
ESB2	6 sol - 2 str.
ESB1/0	4 sol - 1/0 str.
ESB2/0	2 sol - 2/0 str.
ESB4/0	2 sol - 4/0 str.
ESB250	#1 str - 250 KCM
ESB350	250 KCM - 350 KCM
ESB500	400 KCM - 500 KCM

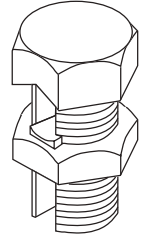

### ERITECH Split Bolts - Tin Plated Silicon Bronze

Part No.	Wire Range
ESBP8	12 sol - 8 str.
ESBP6	10 sol - 6 sol.
ESBP4	10 sol - 4 sol.
ESBP2	6 sol - 1 sol.
ESBP1/0	2 sol - 1/0 str.
ESBP2/0	2 sol - 2/0 str.
ESBP4/0	2 sol - 4/0 str.
ESBP350	250 KCM - 350 KCM
ESBP500	400 KCM - 500 KCM

