



# Equipotential Bonding

## Equipment Ground Bars


ERITECH® EGB Series

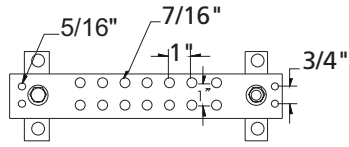


EGBA14212TES (1/4 x 2 x 12)

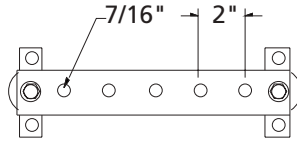


EGBA14212EE (1/4 x 2 x 12)

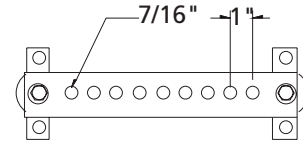


EGBA14212HH (1/4 x 2 x 12)

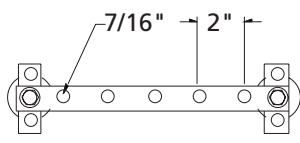


EGBA14112EE (1/4 x 1 x 12)

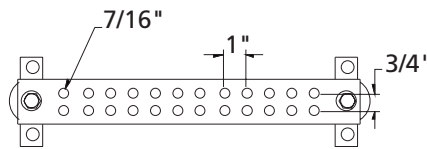

EGBA14215JJ (1/4 x 2 x 15)

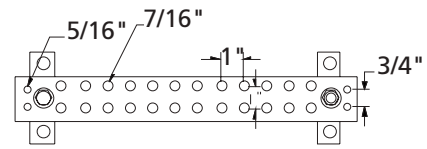


EGBA14215TES (1/4 x 2 x 15)

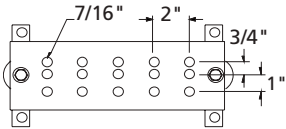


EGBA14412CC (1/4 x 4 x 12)

EGBA14412CCT (1/4 x 4 x 12 tinned)

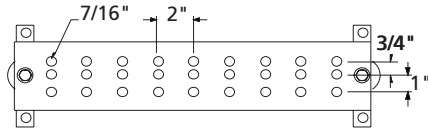


EGBA14420CC (1/4 x 4 x 12)

EGBA144120CCT (1/4 x 4 x 12 tinned)

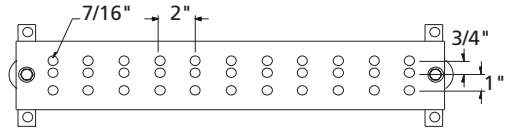


EGBA14424CC (1/4 x 4 x 12)

EGBA144124CCT (1/4 x 4 x 12 tinned)

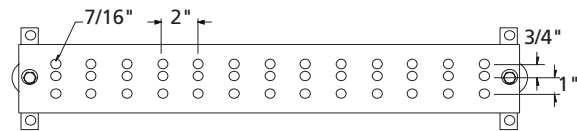


EGBA14428CC (1/4 x 4 x 28)

EGBA144128CCT (1/4 x 4 x 28 tinned)

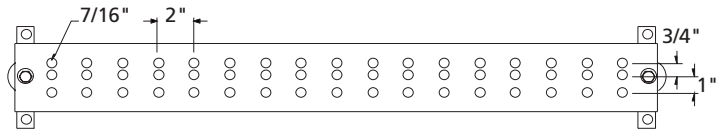


EGBA14436CC (1/4 x 4 x 36)

EGBA144136CCT (1/4 x 4 x 36 tinned)

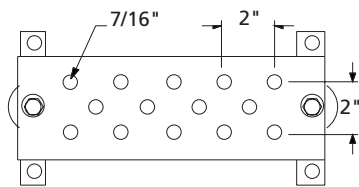


EGBA14412AA

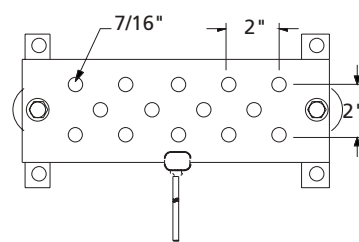


EGBA14412AA1TT (1/4 x 4 x 12 tinned)


(#2 tinned sol pigtail 25ft lg)

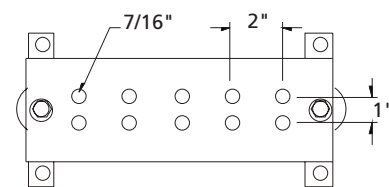


EGBA14412BB (1/4 x 4 x 12)

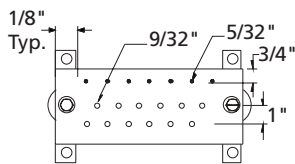

EGBA14410FF (1/4 x 4 x 10)

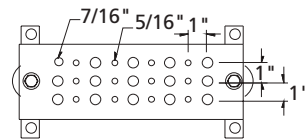

EGBA14412MM (1/4 x 4 x 12)

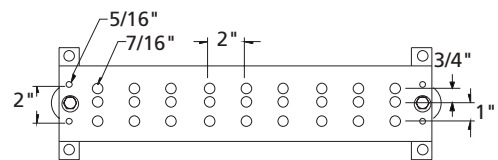

EGBA144120CCSKY (1/4 x 4 x 20)

Figure 31.

