

## Commonly Stocked Copper Grounding Bus Bars\* with Insulators & Brackets



Part No.	Thickness (in)	Width (in)	Length (in)	Hole Pattern
<b>1" wide bar</b>				
EGBA14112EE	1/4	2	12	EE
<b>2" wide bar</b>				
EGBA14212BB	1/4	2	12	BB
EGBA14212EE	1/4	2	12	EE
EGBA14212HH	1/4	2	12	HH
EGBA14212NN	1/4	2	12	NN
EGBA14215JJ	1/4	2	15	JJ
EGBA14224GG	1/4	2	24	GG
EGBA14224NN	1/4	2	24	NN
<b>4" wide bar</b>				
EGBA14410FF	1/4	4	10	FF
EGBA14412AA	1/4	4	12	AA
EGBA14412BB	1/4	4	12	BB
EGBA14412CC	1/4	4	12	CC
EGBA14412GG	1/4	4	12	GG
EGBA14412LL	1/4	4	12	LL
EGBA14412NN	1/4	4	12	NN
EGBA14420CC	1/4	4	20	CC
EGBA14420NN	1/4	4	20	NN
EGBA14424CC	1/4	4	24	CC
EGBA14424LL	1/4	4	24	LL
EGBA14424MM	1/4	4	24	MM
EGBA14424NN	1/4	4	24	NN

\* Also available using pre-tinned copper bar. Add "T" to the part number.

## Mounting Kits




- Include stainless steel hardware, 3/8" fasteners, insulators and brackets
- cULus® listed

Part No.	Description
B548A39*	Mounting kit for steel beam
B548A41	Mounting kit for 1" & 2" wide bars
B548A42	Mounting kit for 3" & 4" wide bars

\* Not UL Listed

## QQ Pattern, Copper and Tinned Copper Grounding Bus Bars with Insulators & Brackets\*

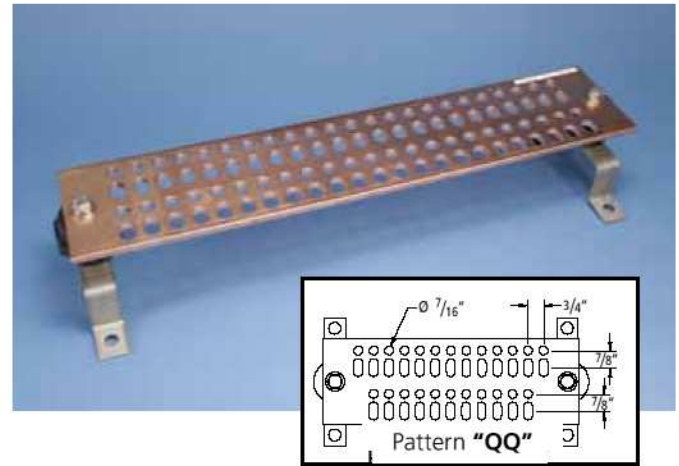

Part No.	Thickness (in)	Width (in)	Length (in)	Hole Pattern	Plating
EGBA14412QQT	1/4	4	12	QQ	Tinned
EGBA14420QQ	1/4	4	20	QQ	Copper
EGBA14420QQT	1/4	4	20	QQ	Tinned
EGBA14424QQ	1/4	4	24	QQ	Copper
EGBA14424QQT	1/4	4	24	QQ	Tinned

## QQ Pattern, Copper & Tinned Copper Grounding Bus Bars (Bar only)\*

Part No.	Configuration	Thickness (in)	Width (in)	Length (in)	Hole Pattern	Plating
EGBC14412QQT	Bar only	1/4	4	12	QQ	Tinned
EGBC14424QQT	Bar only	1/4	4	24	QQ	Tinned
EGBC14420QQ	Bar only	1/4	4	20	QQ	Copper
EGBC14424QQ	Bar only	1/4	4	24	QQ	Copper
EGBC14412QQ	Bar only	1/4	4	12	QQ	Copper

\* Tinned bars with QQ hole pattern are electro-tin plated after holes are punched.

## Ground Bar Insulators



- UL Recognized for Canada and US
- Fiberglass reinforced thermoset polyester

Part No.	Height (in)	Diameter (in) (A)	Thread Size
559600	1	1-1/8	1/4 - 20 x 5/16
559620	1-1/4	1-5/8	1/4 - 20 x 5/16
559660	1-1/2	2	3/8 - 16 x 3/8
559685	2-1/8	2-1/2	5/8 - 11 x 5/8
559686	2-1/4	2-1/2	1/2 - 13 x 5/8
559687	2-1/4	2-1/2	3/8 - 16 x 5/8