

Accessories for Electrical Utility Applications

Along with our main systems and components for the utility industry, ERICO offers a wide range of accessories to assist in grounding, bonding and lightning protection needs.

Ground Rods and Ground Rod Couplers



Complete range of earth/ground rods, and couplers, including copper bonded rods of various size and specification. For complete range and details please refer to the ERITECH® Ground Product catalog.

CADWELD®



Complete range of CADWELD® applications for permanent connections from wire to rod, or wire to wire, etc. For complete range and details please refer to the CADWELD Electrical Connections catalog.

CADWELD® ONE SHOT



Complete range of CADWELD® ONE SHOT applications for permanent connections from wire to rod, or wire to wire. For complete range and details please refer to the CADWELD Electrical connections catalog.

Ground Rod Clamps



SP Series



CP Series



HDC Series

Part No.	Rod Diameter (in)	Conductor Range (AWG)
HDC58*	5/8	8 solid - 1/0 stranded
HDC58R*	5/8	8 solid - 1/0 stranded
HDC34	3/4	8 solid - 1/0 stranded
HDC34SP	3/4	8 solid - 3/0 stranded
CP58	5/8	10 solid - 2 stranded
CP34	3/4	10 solid - 1/0 stranded
SP58	1/2, 5/8	10 solid - 2 stranded
SP58B916**	1/2, 5/9	11 solid - 2 stranded

* HDC58 threads are 1/2" - 13 UNC. HDC58R threads are 7/16" - 14 UNC.

** SP58B916 bolt head is 9/16"

ERITECH® HAMMERLOCK



Part No.	Rod Ø	Conductor Range: Imperial / Metric
EHL58G2G	5/8	1/0 - 2/0 str (50.0 to 70.0 mm² str)
EHL58G1V	5/8	4 - 2 str (22.0 to 35.0 mm² str)
EHL58G1K	5/8	6 - 4 sol (10.0 to 16.0 mm² str)
EHL34G1V	3/4	4 - 2 str (22.0 to 35.0 mm² str)
EHL34SG1V	3/4	4 - 2 str (22.0 to 35.0 mm² str)
EHL34G1K	3/4	6 - 4 sol (10.0 to 16.0 mm² str)
EHL34SG1K	3/4	6 - 4 sol (10.0 to 16.0 mm² str)
Dual-Hole (2 Conductors)		
EHL58G1K1K	5/8	6 - 4 sol (10.0 to 16.0 mm² str)


Utility Grounding Bars



EGB Series

Various material, coating and configurations – contact ERICO for your specific needs.

Ground Enhancement Material (GEM)

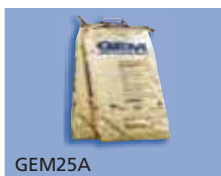

GEM25A



GEM25ABKT

GEM25A: 25 lb (11.36 kg) bag of GEM

GEM25ABKT: 25 lb (11.36 kg) bucket of GEM

Technical support is available to help estimate the quantity of GEM needed for any installation – contact ERICO for your specific needs.

Theft Deterrent Cable



Part No.	Description
CC5A04	Theft deterrent composite cable, 7 strand, 0.330" outside diameter, 250' reel
CC5A05	Theft deterrent composite cable, 19 strand, 0.334" outside diameter, 250' reel
CC5A12	Theft deterrent composite cable, 157 strand, 0.572" outside diameter, 200' reel
CCL04A	Aluminum composite cable clip for theft deterrent composite cable



CCL04A

A range of MTO copper-bonded, pre-formed or coiled steel conductors is available.

