

Products

[BC13 Welded Beam Clamp, Standard Duty](#)

BC13 Welded Beam Clamp, Standard Duty

BC130025EG

[All Countries](#) [Change](#)

[Print this page](#)



Features

- Structural attachment to beams to support threaded rod




Product Specifications

Part Number	BC130025EG
Material	Steel
Finish	Electrogalvanized
Rod Size (RS)	1/4"
Flange Thickness (FT)	7/8" Max
B	1 1/8"
Screw Diameter (Sc)	3/8"
Screw Length (L)	1 3/4"
Torque (TQ)	5 ft lb
Static Load (F)	650 lb
Standard Packaging Quantity	20 pc
UPC	78285634009

UNSPSC	31162905
ETIM	EC000464

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

Recognizing that torque wrenches are generally not used or available on many job sites, the setscrew should be tightened so it contacts the I-beam and then an additional 1/4 to 1/2 turn added.

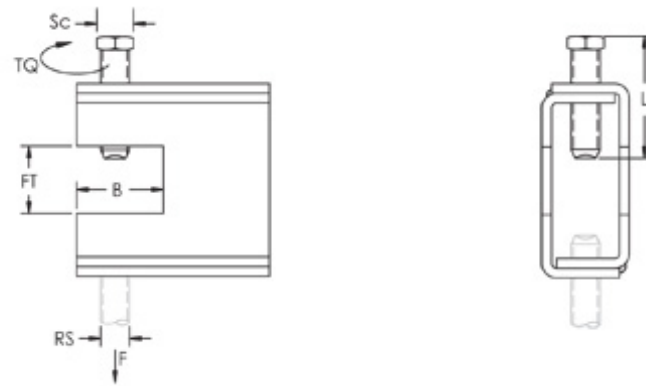




Application Photos





Downloads

Catalogs

-  [CADDY® Electrical and Low Voltage/Datacomm Fasteners](#)
6.59 MB English
-  [CADDY® Mechanical Hangers and Supports for Plumbing, HVAC and Fire Protection Catalog](#)
9.42 MB English
-  [CADDY® Soportes mecánicos para plomería, calefacción / ventilación / aire acondicionado \(HVAC\) y protección contra incendios](#)
7.29 MB Español
-  [Supports et attaches mécaniques pour plomberie, chauffage, climatisation et protection incendie](#)
29.88 MB Français

Warning, Warranty and Limitation of Liability

Due to a policy of continued product development, specifications are subject to change without notice.
CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.