

Products

CADDY® CABLECAT J-Hook with Hammer-On Flange Clip, Swivel

CADDY® CABLECAT J-Hook with Hammer-On Flange Clip, Swivel

CAT21912 (181700)

 [All Countries](#) [Change](#)

 [Print this page](#)



Features


- Hammer-on beam clamp with attached CADDY® CABLECAT J-Hook
- Supports low voltage cables
- Swivels to support various directional runs of cable



Product Specifications

Part Number	CAT21912
Article Number	181700
Material	Steel
Finish	Pregalvanized, CADDY® ARMOUR
Diameter (Ø)	1 5/16", 33 mm
Flange Thickness (FT)	9/16" – 3/4", 14 – 19 mm
Standard Packaging Quantity	20 pc
UPC	78285630238
UNSPSC	39131709
EAN-13	8711893118773

ETIM	EC000754
Certifications	cULus

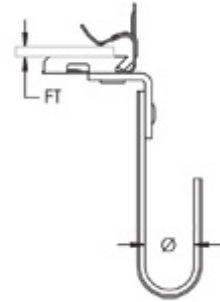

Application Photos





Downloads

Catalogs

 [CADDY® Electrical and Low Voltage/Datacomm Fasteners](#)
6.59 MB English

Certifications

 [cUL DWMU7.E165703](#)
CAN/CSA C22.2 No. 18.4-04

 [UL DWMU.E165703](#)
ANSI/UL 2239

Warning, Warranty and Limitation of Liability

Due to a policy of continued product development, specifications are subject to change without notice.
CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.