

Products

CADDY® CABLECAT J-Hook with Pin Driven Angle Bracket

CADDY® CABLECAT J-Hook with Pin Driven Angle Bracket

CAT21AFAB4

[Print this page](#)

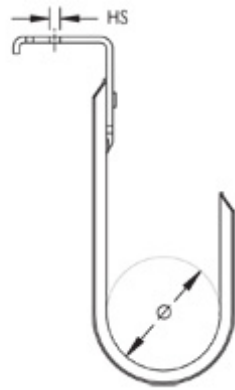

Features

- Angle bracket support with attached CADDY® CABLECAT J-Hook
- Supports low voltage cables



Product Specifications

Part Number	CAT21AFAB4
Material	Steel
Finish	Pregalvanized
Diameter (Ø)	1 5/16", 19 mm
Hole Size (HS)	1/4", 6 mm
Standard Packaging Quantity	40 pc
UPC	78285643899
UNSPSC	39131709
Certifications	cULus



Downloads

Catalogs

 [CADDY® Electrical and Low Voltage/Datacomm Fasteners](#)
6.59 MB English

 [CADDY® Electrical and Low Voltage/Datacomm Fasteners](#)

CERTIFICATIONS

 [cUL DWMU7.E165703](#)
CAN/CSA C22.2 No. 18.4-04

 [UL DWMU.E165703](#)
ANSI/UL 2239

Warning, Warranty and Limitation of Liability

Due to a policy of continued product development, specifications are subject to change without notice.
CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

