



CATMT CATMTP

Red CADDY Mille-Tie (suitable for air-handling spaces)

Application Information

- CADDY Mille-Tie cannot be over-tightened. The tie forms a smooth contour around the cables to eliminate gaps and pinch points, greatly reducing the chance of detrimental hot spots forming in the cable. They are easy to install, leave no sharp edges when cut and can be quickly removed by hand. Additionally, one strip can replace four or five conventional ties, reducing stock requirements and waste and speeding installation.
- Plenum-rated for air-handling spaces.
- The CADDY® Mille-Tie from ERICO® is the 21st century method of quickly and economically bundling and positioning high-performance copper and fiber cable. The ties are ideal for use on power cables, conduit, innerduct, AC/MC cable in cable trays, non-continuous fasteners (J-Hooks, etc.), surface raceways, wireways, service poles and in-wall cabling. They separate cables for voice, data, video, alarm and building automation systems in horizontal and backbone pathways, simplifying installation and identification for testing and troubleshooting.
- The innovative design of the CADDY Mille-Tie helps protect cables from installation damage and promote maximum signal throughput. "Intelligent grip" technology naturally controls and adjusts the level of tension to help ensure the perfect grip. CADDY Mille-Tie holds cables in place and reduces the risk of compression damage and slippage problems often associated with traditional nylon and fabric cable ties.




Features

- Suitable for air-handling spaces (Plenum).
- Maintains cable properties and conductor configuration
- Protects cable from crimping with "Intelligent Grip Technology"
- Cushions vibration
- No sharp edges
- One size fits all
- Reusable

Product Specifications

Bag Qty	100
Patent Number	5,740,994
Standard Packaging Quantity	1000
Weight per Box (lb)	5.00 lbs

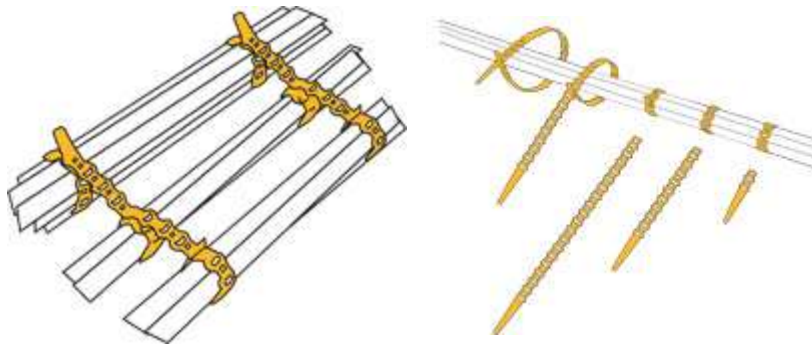

Application Photos



WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

WARRANTY

ERICO products are warranted to be free from defects in material and workmanship at the time of shipment. NO OTHER WARRANTY, WHETHER EXPRESS OR IMPLIED (INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE), SHALL EXIST IN CONNECTION WITH THE SALE OR USE OF ANY ERICO PRODUCTS. Claims for errors, shortages, defects or nonconformities ascertainable upon inspection must be made in writing within 5 days after Buyer's receipt of products. All other claims must be made in writing to ERICO within 6 months from the date of shipment or transport. Products claimed to be nonconforming or defective must, upon ERICO's prior written approval in accordance with its standard terms and procedures governing returns, promptly be returned to ERICO for inspection. Claims not made as provided above and within the applicable time period will be barred. ERICO shall in no event be responsible if the products have not been stored or used in accordance with its specifications and recommended procedures. ERICO will, at its option, either repair or replace nonconforming or defective products for which it is responsible or return the purchase price to the Buyer. THE FOREGOING STATES BUYER'S EXCLUSIVE REMEDY FOR ANY BREACH OF ERICO WARRANTY AND FOR ANY CLAIM, WHETHER SOUNDING IN CONTRACT, TORT OR NEGLIGENCE, FOR LOSS OR INJURY CAUSED BY THE SALE OR USE OF ANY PRODUCT.

LIMITATION OF LIABILITY

ERICO excludes all liability except such liability that is directly attributable to the willful or gross negligence of ERICO's employees. Should ERICO be held liable its liability shall in no event exceed the total purchase price under the contract. ERICO SHALL IN NO EVENT BE RESPONSIBLE FOR ANY LOSS OF BUSINESS OR PROFITS, DOWNTIME OR DELAY, LABOR, REPAIR OR MATERIAL COSTS OR ANY SIMILAR OR DISSIMILAR CONSEQUENTIAL LOSS OR DAMAGE INCURRED BY BUYER.

Due to a policy of continued product development, specifications are subject to change without notice.

Copyright © 2013 ERICO International Corporation.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

ERICO[®]