
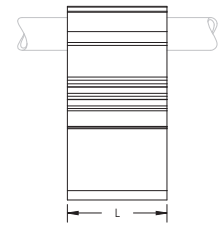


CADDY® PYRAMID EZ Rubber-Based Support – RPSE1H57 (182370)

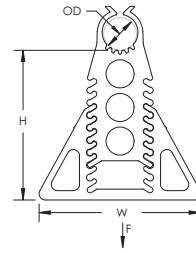

CADDY® PYRAMID EZ rubber-based supports feature a wide platform base design to provide reliable support and distribute load across roof surface. These versatile supports are fast and easy to install compared to wood blocks and metal straps.

- Quick height adjustment accommodates for uneven roofs or sloped condensate lines
- No tools or fasteners needed; fast snap-on installation
- Design sheds water and helps reduce pipe corrosion
- Roof-friendly; made of UV-stabilized EPDM material

Part Number	RPSE1H57
Article Number	182370
Material	EPDM-SBR Rubber
Rigid Conduit/Pipe Size	1"
NB/DN	25
Outer Diameter (OD)	1.315" 33 mm
Height (H)	5" – 7" 127 – 178 mm
Length (L)	4" 102 mm
Width (W)	6" 152 mm
Unit Weight	3 lb 1.3 kg
Ultimate Static Load (F)	170 lb 756 N
Standard Packaging Quantity	10 pc
UPC	78285666333
UNSPSC	30151609
EAN-13	8711893064964
ETIM	EC011776

Ultimate load at 1/4" (6.35 mm) deflection. Contact project or roofing engineer for maximum allowable load on individual project roof system.

WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

Copyright © 2014 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

