



## CADDY® SPEED LINK 3.0 mm SLD3L2

CADDY® SPEED LINK 3mm (.118 IN) diameter x 2M (6.6 FT) length; Hook end

### Ordering Information

Region	Part / Article #
North America	SLD3L2
Latin America	SLD3L2
Europe/Middle East/Africa	195830
Asia/Australia	195830




### Features

- 5:1 Safety Factor
- Meets the fire rating requirements for DIN 4102-2 for 30 minutes at 30% of rated load
- Size Range: 0.079" and 0.118" wire rope
- Tested and found to be acceptable alternative to the duct hanger systems prescribed in the SMACNASM HVAC Duct Construction Standards (HVAC-DCS), 2nd Edition, Chapter 4, Tables 4-1, 4-1M, 4-2 and 4-2M
- Universal support system recommended for the suspension of ductwork, piping or equipment
- Allows for easy adjustments of supported objects both during and after installation
- Increases installation versatility by allowing objects to be hung at an angle
- Minimizes vibration and system wear and tear with a strong, yet flexible wire rope
- Reduces installation time and inventory
- Works with a variety of CADDY® Fasteners or as a stand-alone system without drilling into the building structure



### Product Specifications

<b>Bulk Pack</b>	10x10
<b>Finish</b>	Electro-zinc plated
<b>Material</b>	Galvanized Steel
<b>Series</b>	CADDY® SPEED LINK
<b>Standard Packaging Quantity</b>	100
<b>Third Party Certifications</b>	cULus® SMACNA
<b>Type</b>	HOOK
<b>Wire Rope Diameter (in)</b>	0.118"
<b>Wire Rope Diameter (mm)</b>	3.0 mm

Wire Rope Length (ft)	6.6'
Wire Rope Length (m)	2 m
Working Load (kg)	90 kg
Working Load (lbs)	200 lbs
Working Load (N)	880 N

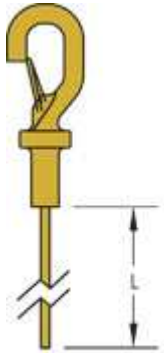

### Application Photos

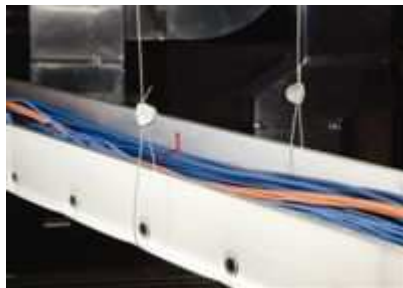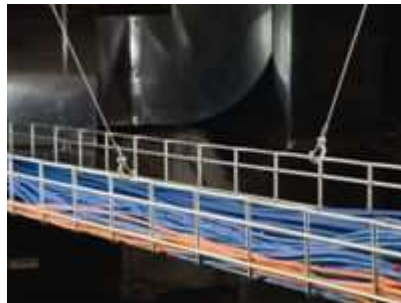

**WARNING**

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

**WARRANTY**

ERICO products are warranted to be free from defects in material and workmanship at the time of shipment. NO OTHER WARRANTY, WHETHER EXPRESS OR IMPLIED (INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE), SHALL EXIST IN CONNECTION WITH THE SALE OR USE OF ANY ERICO PRODUCTS. Claims for errors, shortages, defects or nonconformities ascertainable upon inspection must be made in writing within 5 days after Buyer's receipt of products. All other claims must be made in writing to ERICO within 6 months from the date of shipment or transport. Products claimed to be nonconforming or defective must, upon ERICO's prior written approval in accordance with its standard terms and procedures governing returns, promptly be returned to ERICO for inspection. Claims not made as provided above and within the applicable time period will be barred. ERICO shall in no event be responsible if the products have not been stored or used in accordance with its specifications and recommended procedures. ERICO will, at its option, either repair or replace nonconforming or defective products for which it is responsible or return the purchase price to the Buyer. THE FOREGOING STATES BUYER'S EXCLUSIVE REMEDY FOR ANY BREACH OF ERICO WARRANTY AND FOR ANY CLAIM, WHETHER SOUNDING IN CONTRACT, TORT OR NEGLIGENCE, FOR LOSS OR INJURY CAUSED BY THE SALE OR USE OF ANY PRODUCT.

**LIMITATION OF LIABILITY**

ERICO excludes all liability except such liability that is directly attributable to the willful or gross negligence of ERICO's employees. Should ERICO be held liable its liability shall in no event exceed the total purchase price under the contract. ERICO SHALL IN NO EVENT BE RESPONSIBLE FOR ANY LOSS OF BUSINESS OR PROFITS, DOWNTIME OR DELAY, LABOR, REPAIR OR MATERIAL COSTS OR ANY SIMILAR OR DISSIMILAR CONSEQUENTIAL LOSS OR DAMAGE INCURRED BY BUYER.

Due to a policy of continued product development, specifications are subject to change without notice.

Copyright © 2013 ERICO International Corporation.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.