

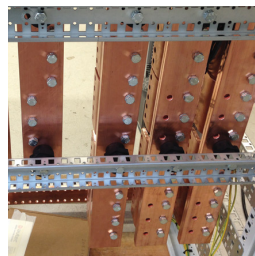
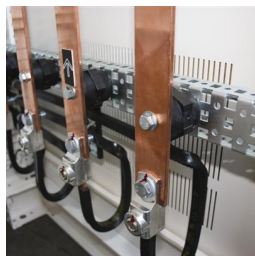
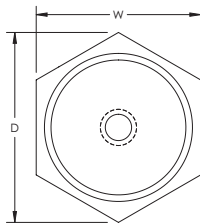


ISO-TP Low Voltage Insulators, Metric Thread – ISOTP35M8 (548480)

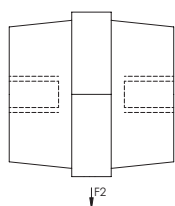

- Halogen free
- High resistance to leakage current
- Great stability of electrical and mechanical parameters
- Fiberglass reinforced
- UL® Recognized in E125470 and evaluated for dielectric withstand rating of 1,500 VAC/DC
- RoHS compliant

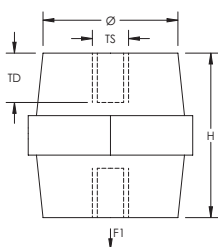

Part Number	ISOTP35M8
Article Number	548480
Material	Glass Fibre Reinforced Polyamide Steel
Finish	Electrogalvanized
Working Temperature	-40 to 130 °C
Flammability Rating	UL® 94V-0
Height (H)	35 mm
Hex Width (W)	41 mm
Depth (D)	46 mm
Thread Size (TS)	M8
Thread Depth (TD)	8 mm
Diameter (Ø)	34 mm
Insulation Voltage	1,000 VAC 1,500 VDC
Static Load 1 (F1)	11,000 N
Static Load 2 (F2)	8,000 N
Unit Weight	0.074 kg
Certifications	CE cURus IEC 61439-1 ISO-TP Insulators



Part Number	ISOTP35M8
Standard Packaging Quantity	25 pc
UPC	78285663689
EAN-13	3479775484808

Creepage and clearance distances need to be in accordance with the relevant application standard.

IEC is a registered trademark of the International Electrotechnical Commission. UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

Copyright © 2015 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

