

 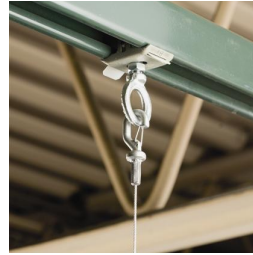
 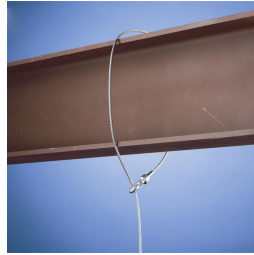


# CADDY SPEED LINK LD with Hook – SLD15L10S



- Complete system includes wire, locking device and pre-assembled hook end fitting
- Hooks to a wide range of CADDY fasteners
- Fastens to the building structure or hanging services by looping around and hooking to wire rope
- Easy to remove for applications requiring maintenance
- Spring latch helps provide secure connection
- Insert cable through hole and use bottom side of hook as an end stop



Part Number	SLD15L10S
Material	Stainless Steel 304 (EN 1.4301)
Static Load Safety Factor	5:1
Wire Rope Diameter	1.5 mm
Wire Rope Length	32.8'
A	2.3"
B	0.9"
C	1/4"
Static Load (F)	44 lb
Height (H)	3/4"
Width (W)	1/2"
Certifications	cULus
Standard Packaging Quantity	20 x 2 pc
UPC	78285657523
EAN-13	8711893038958

