


MICROSTAT® OPTIONAL EQUIPMENT

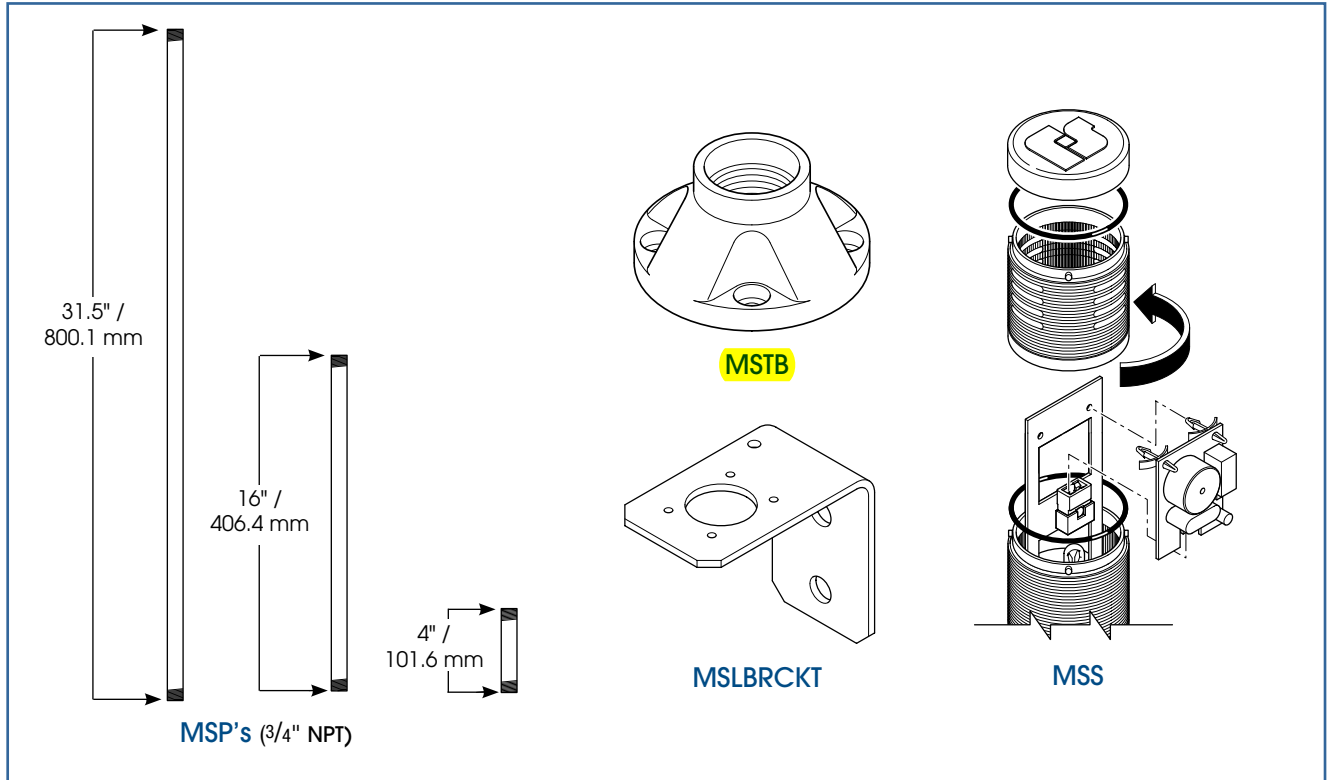

SPECIFICATIONS

MSS

Operating Current:	24VDC	0.03 amps
	120VAC	0.04 amps
dBa Output:	93-95dBa @ 10'	83-85 @ 1m
Net Weight:	0.25 lbs.	0.11 kg
Shipping Weight:	0.75 lbs.	0.34 kg
Height:	2.0"	50.8 mm
Diameter:	2.2"	55.9 mm

MSLED

Operating Current:	24VDC	0.095 amps
	120VAC	0.095 amps
Net Weight:	0.05 lbs.	0.02 kg
Shipping Weight:	0.55 lbs.	0.25 kg
Height:	1.75"	44.45 mm
Width:	1.5"	38.1 mm

REPLACEMENT PARTS

<u>Description</u>	<u>Part Number</u>
LED Lamp, Amber	MSLED-A
LED Lamp, Blue	MSLED-B
LED Lamp, Clear	MSLED-C
LED Lamp, Green	MSLED-G
LED Lamp, Red	MSLED-R

MSLBRCCT

Net Weight:	0.4 lbs.	0.18 kg
Shipping Weight:	0.9 lbs.	0.41 kg
Height:	3.45"	87.63 mm
Width:	2.0"	50.8 mm

MSTB

Net Weight:	0.3 lbs.	0.14 kg
Shipping Weight:	0.8 lbs.	0.36 kg
Height:	1.5"	38.1 mm
Diameter:	2.75"	1.25 mm

HOW TO ORDER

- Specify model
- Specify voltage for sound modules and flashers
- Specify color for LED lamps

Description

Flasher, 24VDC
Flasher, 120VAC

Part Number

K8285237A
K8285239A