

A240R

MEDIUM VOLTAGE FUSES/R-RATED

2.4kV Ferrule Style

Indicator Flush with Surface
2 Lb. Force (Tripped)

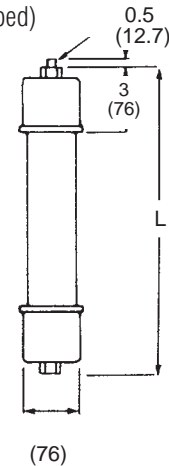


Figure A

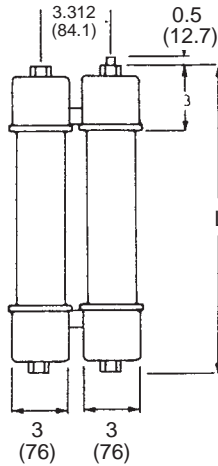


Figure B

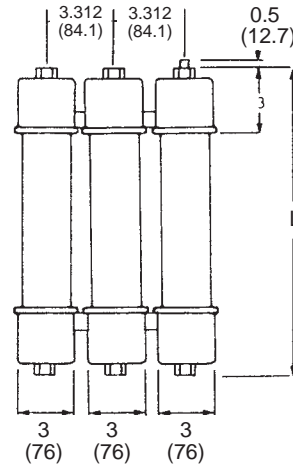


Figure C



Catalog Numbering System, Ratings, Dimensions, 2.4kV

FIG.	CATALOG NUMBER	SIZE	CONTINUOUS AMPERE RATING at 40 °C	DIM. L	MINIMUM INTERRUPTING RATING RMS AMPERES	1 PHASE INTERRUPTING RATING				
						UL COMPONENTS RECOGNITION		MAXIMUM TESTED		
	STANDARD					RMS Asym	RMS Sym	RMS Asym	RMS Sym	
A240R										
A	A240R1R	1R	35	10-7/8 (276mm)	100	100kA	@ 2600V	@ 2600V	100kA	@ 2750V
	A240R2R	2R	70		170					
	A240R3R	3R	100		250					
	A240R4R	4R	130		340					
	A240R5R	5R	150		420					
	A240R6R	6R	170		500					
	A240R9R	9R	200	760						
	A240R12R	12R	230	1000						
B	A240R18R	18R	390	1500						
C	A240R24R	24R	450	2000						
	A240R36R	36R**	650	2900						

* This rating defines the fuse's long-term thermal capability per ANSI C37. 46-1 and should not be the sole factor for selecting a specific R rating.

** Not recommended for use in fuse clips which grasp only one barrel.