



TR50VA017

Transformer 50 VA, 480/277/208 to 24 Vac, Circuit Breaker, Foot and Single Threaded Hub Mount

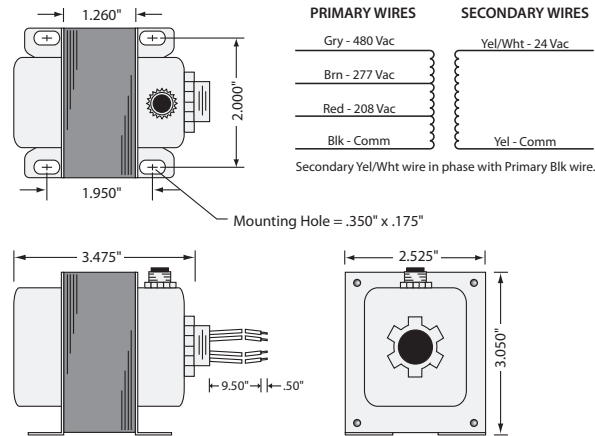

Transformer

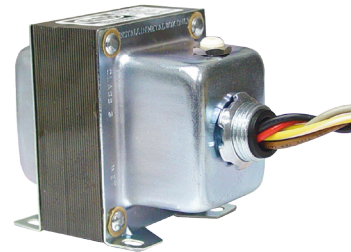

Specifications

- VA Rating:** 50
- Frequency:** 50/60 Hz
- Mounting:** Foot & Single Threaded Hub
- Over Current Protection:** Circuit Breaker
- Dimensions:** 3.050" x 2.525" x 3.475"
(w/ .500" NPT Hub)
- Wire Length:** 9.5" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
- MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 2.86 lbs.
- Approvals:** Class 2 UL5085-3 Listed, C-UL, CE, RoHS