


**Catalog No. 0176D7926G001**

**Description: LV SWGR SEC DISCONN ASSEMBLY**

**UPC No 783164432596**

**Products > Circuit Breakers > Low Voltage Circuit Breakers > Burlington - AK/AKR**

AK/AKR low-voltage power circuit breakers are intended for use in commercial, industrial and utility applications. Designed for severe duty, AKR breakers are serviceable and suitable for mains, feeders and applications such as motor starting, capacitor switching/generator protection and resistance welding. They are fully rated; that is, the short time rating in most cases is equal to the short circuit rating providing the greatest opportunity for selectivity with downstream devices. The breakers are maintainable and meet ANSI Standard C37.13 and C37.16, as well as applicable UL Standards. There are five frame sizes from 800-4000 amperes with short circuit interrupting ratings to 200 kA symmetrical short circuit without fuses.

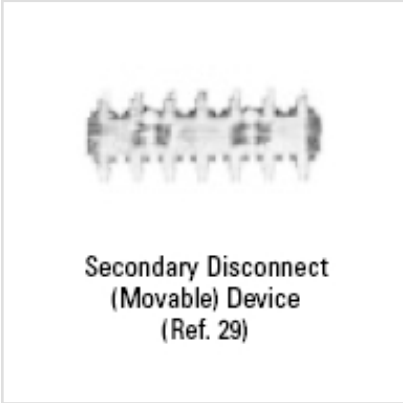

**Descriptors**

Category	Burlington - AK/AKR
----------	---------------------

**Specifications**

Frame Type	AKJ, AKJT, AKJU, AKR, AKRT, AKRU, AKS, AKST, AKSU
Model/Type	AKJ-50, AKJ-50H, AKJT-50H, AKJU-50, AKR-100, AKR-30, AKR-30H, AKR-30S, AKR-50, AKR-50H, AKR-75, AKRT-50H, AKRU-30, AKRU-30S, AKRU-50, AKS-50, AKS-50H, AKST-50H, AKSU-50
Legacy GO Code	129SS