

Molded Case Circuit Breakers Industrial Circuit Breakers


Section 6

300-1200A Circuit Breakers

Electronic Trip

Spectra™ RMS

Product Number Structure

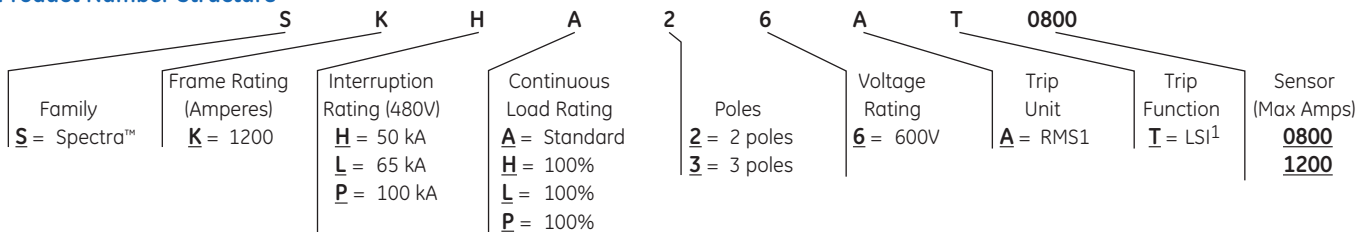

¹Adjustable Instantaneous with Tracking Short Time (Long Time established via Interchangeable Rating Plugs).

Note: This information is provided for interpreting product numbers (it should not be used to build product numbers).

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350, UL/CSA: 800A, 600 Vac Max., IEC 947-2:800A 690 Vac Max.

Rating Plug				Frame				Terminal Lugs for Front Connection (Cu/Al)	
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	Current Sensor	Poles	UL 489 IC @480 Vac		Product Number	Wire Range
	Low	High				50kA	65kA		
300	940	3015	SRPK800A300	800	2	SKHA26AT0800	SKLA26AT0800	TCAL81	(3) 3/0-500 Cu
400	1255	4015	SRPK800A400						
500	1570	5020	SRPK800A500						
600	1875	6195	SRPK800A600						
700	2155	7420	SRPK800A700						
800	2440	8705	SRPK800A800		3	SKHA36AT0800	SKLA36AT0800		

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350, UL/CSA: 800A, 600 Vac Max., IEC 947-2:800A 690 Vac Max.

Rating Plug				Frame				Terminal Lugs for Front Connection (Cu/Al)	
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	Current Sensor	Poles	UL 489 IC @480 Vac		Product Number	Wire Range
	Low	High				100kA			
300	940	3015	SRPK800A300	800	2	SKPA26AT0800	TCAL81	(3) 3/0-500 Cu	
400	1255	4015	SRPK800A400						
500	1570	5020	SRPK800A500						
600	1875	6195	SRPK800A600						
700	2155	7420	SRPK800A700						
800	2440	8705	SRPK800A800		3	SKPA36AT0800			(3) 3/0-500 Al

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350, UL/CSA: 1200A, 600 Vac Max., IEC 947-2: 1250A, 690 Vac Max.

Rating Plug				Frame				Terminal Lugs for Front Connection (Cu/Al)	
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	Current Sensor	Poles	UL 489 IC @480 Vac		Product Number	Wire Range
	Low	High				50kA	65kA		
600	1825	6110	SRPK1200A600	1200	2	SKHA26AT1200	SKLA26AT1200	TCAL125	(4) 250-500 Cu
700	2125	7125	SRPK1200A700						
800	2430	8145	SRPK1200A800						
900	2735	9160	SRPK1200A900						
1000	3040	10180	SRPK1200A1000						
1200	3650	12215	SRPK1200A1200		3	SKHA36AT1200	SKLA36AT1200		

SK1200 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350, UL/CSA: 1200A, 600 Vac Max., IEC 947-2: 1250A, 690 Vac Max.

Rating Plug				Frame				Terminal Lugs for Front Connection (Cu/Al)	
Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Product Number	Current Sensor	Poles	UL 489 IC @480 Vac		Product Number	Wire Range
	Low	High				100kA			
600	1825	6110	SRPK1200A600	1200	2	SKPA26AT1200	TCAL125	(4) 250-500 Cu	
700	2125	7125	SRPK1200A700						
800	2430	8145	SRPK1200A800						
900	2735	9160	SRPK1200A900						
1000	3040	10180	SRPK1200A1000						
1200	3650	12215	SRPK1200A1200		3	SKPA36AT1200			(4) 250-500 Al

Note: All Spectra™ breakers UL listed as HACR type.

All Spectra™ breakers marked CE.

