


# Molded Case Circuit Breakers Industrial Circuit Breakers

15-150A Circuit Breakers  
Electronic Trip  
Spectra™ RMS  
SE150 Line Circuit Breakers

### Product Number Structure

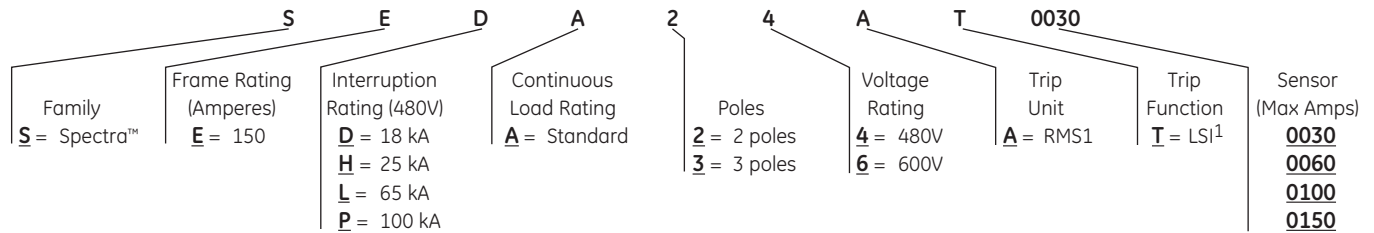

<sup>1</sup>Adjustable Instantaneous with Tracking Short Time (Long Time established via Interchangeable Rating Plugs).  
Note: This information is provided for interpreting product numbers (it should not be used to build product numbers).

### SE150 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350

SED, SEH; 2-Pole, UL/CSA: 150A, 480 Vac Max., IEC 947-2: 160A, 415 Vac Max.

Rating Plug				Frame			Terminal Lugs for Front Connection (Cu/Al)	
Ampere Rating	Adj. Inst. Trip Range Amps		Product Number	Current Sensor	UL 489 IC @480 Vac	UL 489 IC @480 Vac	Product Number	Wire Range
	Low	High			18kA Product Number	25kA Product Number		
15	43	182	SRPE30A15	30	SEDA24AT0030 <sup>3</sup>	SEHA24AT0030 <sup>3</sup>	TCAL18	12-3/0 Cu 12-3/0 Al
20	58	254	SRPE30A20					
25	73	332	SRPE30A25					
30	87	415	SRPE30A30					
40	118	501	SRPE60A40	60	SEDA24AT0060 <sup>3</sup>	SEHA24AT0060 <sup>3</sup>		
50	148	637	SRPE60A50					
60	178	777	SRPE60A60					
70	206	863	SRPE100A70	100	SEDA24AT0100	SEHA24AT0100		
80	236	999	SRPE100A80					
90	267	1138	SRPE100A90					
100	297	1280	SRPE100A100					
110	328	1426	SRPE150A110	150	SEDA24AT0150	SEHA24AT0150		
125	374	1640	SRPE150A125					
150	450	1991	SRPE150A150					

### SE150 Line, Suitable for Reverse Feed, UL File E-11592, CSA LR 40350

SEL, SEP<sup>2</sup>; 2-Pole, UL/CSA: 150A, 480 Vac Max., IEC 947-2: 160A, 415 Vac Max.

Rating Plug				Frame			Terminal Lugs for Front Connection (Cu/Al)	
Ampere Rating	Adj. Inst. Trip Range Amps		Product Number	Current Sensor	UL 489 IC @480 Vac	UL 489 IC @480 Vac	Product Number	Wire Range
	Low	High			65kA Product Number	100kA Product Number		
15	43	182	SRPE30A15	30	SELA24AT0030 <sup>3</sup>	SEPA24AT0030 <sup>3</sup>	TCAL18	12-3/0 Cu 12-3/0 Al
20	58	254	SRPE30A20					
25	73	332	SRPE30A25					
30	87	415	SRPE30A30					
40	118	501	SRPE60A40	60	SELA24AT0060 <sup>3</sup>	SEPA24AT0060 <sup>3</sup>		
50	148	637	SRPE60A50					
60	178	777	SRPE60A60					
70	206	863	SRPE100A70	100	SELA24AT0100	SEPA24AT0100		
80	236	999	SRPE100A80					
90	267	1138	SRPE100A90					
100	297	1280	SRPE100A100					
110	328	1426	SRPE150A110	150	SELA24AT0150	SEPA24AT0150		
125	374	1640	SRPE150A125					
150	450	1991	SRPE150A150					

<sup>2</sup>SEL, SEP UL current limiting.

<sup>3</sup>When used with 15-50A Rating Plug, UL listed for HID (high intensity discharge).

Note: All Spectra™ breakers UL listed as HACR type.

All Spectra™ breakers marked CE.

