



Molded Case Circuit Breakers Industrial Circuit Breakers

Section 6

125-600A Circuit Breakers
Thermal-Magnetic Trip
J600 Line Circuit Breakers
Types TJJ, TJK, THJK

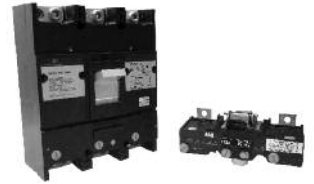

Product Number Structure

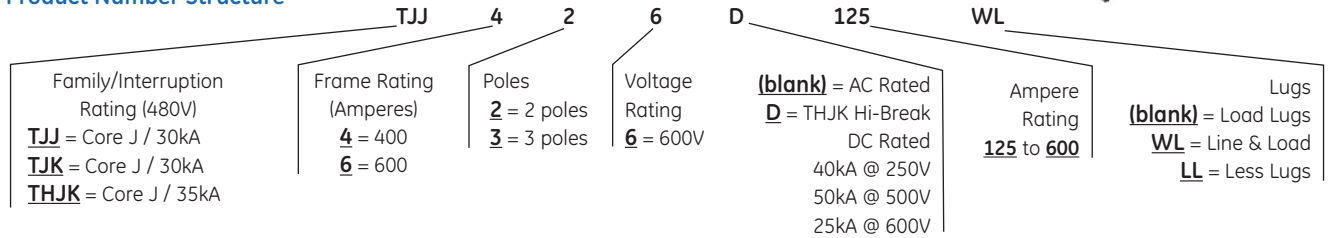

Note: This information is provided for interpreting product numbers (it should not be used to build product numbers).

Type TJJ Noninterchangeable Trip, includes Cu/Al Line and Load Lugs, suitable for reverse feed

Ampere Rating	Adjustable Instantaneous Trip Ampere Range		Frame		Terminal Lugs for Front Connection (Cu/Al)	
	Low	High	2-Pole, 400 Ampere Frame 600 Vac, 250 Vdc	3-Pole, 400 Ampere Frame 600 Vac	Copper/ Aluminum Lugs	Wire Size
			Product Number	Product Number		
125	375	1250	TJJ426125WL	TJJ436125WL	TCAL43 ³ Included in price of breaker	(1) 6-600 or (2) 2/0-250 Cu/Al
150	450	1500	TJJ426150WL	TJJ436150WL		
175	525	1750	TJJ426175WL	TJJ436175WL		
200	600	2000	TJJ426200WL	TJJ436200WL		
225	675	2250	TJJ426225WL	TJJ436225WL		
250	750	2500	TJJ426250WL	TJJ436250WL		
300	900	3000	TJJ426300WL	TJJ436300WL		
350	1050	3500	TJJ426350WL	TJJ436350WL		
400	1200	4000	TJJ426400WL	TJJ436400WL		

Types TJK, THJK – Interchangeable Trip, includes Cu/Al Line and Load Lugs, not suitable for reverse feed

Ampere Rating	Adjustable Instantaneous Trip Ampere Range			Standard Product Number	Complete Circuit Breaker Includes Line and Load Lugs			Terminal Lugs for Front Connection (Cu/Al) ¹	
	Low	High	Hi-Break Product Number		Frame Only Product Number	Trip Unit Only. Use with Standard and Hi-Break Frames	Product Number (Order 2 per pole)	Wire Size	
400A Frame—Two-Pole									
125	375	1250	TJK426125WL	THJK426125WL	TJK426F000 Standard Frame	TJK426T125	TCAL43 ³	(1) 6-600 or (2) 2/0-250 Cu/Al	
150	450	1500	TJK426150WL	THJK426150WL		TJK426T150			
175	525	1750	TJK426175WL	THJK426175WL		TJK426T175			
200	600	2000	TJK426200WL	THJK426200WL		TJK426T200			
225	675	2250	TJK426225WL	THJK426225WL		TJK426T225			
250	750	2500	TJK426250WL	THJK426250WL		TJK426T250			
300	900	3000	TJK426300WL	THJK426300WL		TJK426T300			
350	1050	3500	TJK426350WL	THJK426350WL		TJK426T350			
400	1200	4000	TJK426400WL	THJK426400WL		TJK426T400			
400A Frame—Three-Pole									
125	375	1250	TJK436125WL	THJK436125WL	TJK436F000 Standard Frame	TJK436T125	TCAL43 ³	(1) 6-600 or (2) 2/0-250 Cu/Al	
150	450	1500	TJK436150WL	THJK436150WL		TJK436T150			
175	525	1750	TJK436175WL	THJK436175WL		TJK436T175			
200	600	2000	TJK436200WL	THJK436200WL		TJK436T200			
225	675	2250	TJK436225WL	THJK436225WL		TJK436T225			
250	750	2500	TJK436250WL	THJK436250WL		TJK436T250			
300	900	3000	TJK436300WL	THJK436300WL		TJK436T300			
350	1050	3500	TJK436350WL	THJK436350WL		TJK436T350			
400	1200	4000	TJK436400WL	THJK436400WL		TJK436T400			
400	600	2000	—	—		TJK436TM1400 ²			
Mag	1200	4000	—	—	TJK436TM2400 ²				
Only	350	1000	—	—	TJK436TM3400 ²				

¹For optional lugs, see page 6-106.

²Not UL listed.

³Alternate lug for 750 kcmil Cu/Al cable, Product Number TCAL47.

Accessories: See pages 6-39 to 6-44 and 6-97 to 6-109.

