


# Molded Case Circuit Breakers

## External Accessories

### Door-Mounted Operators

## Section 6

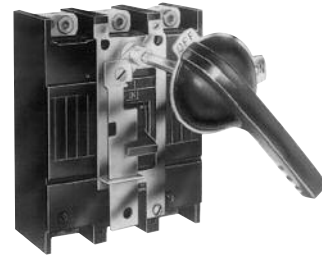

TDM Operating Handle, Fixed or Adjustable Shaft

### TDM Handle Operating Mechanisms, Door Mounted

Complete mechanism with handle UL listed, E-57253

Operating mechanism only, UL Component Recognized, E-57253

| Breaker Type                               | Box Depth in Inches                | Complete Mechanism <sup>1</sup><br>with NEMA 1, 3R, 12 Handle<br>Product Number | Operating Mechanism Only<br>Product Number | Handle Only                      |                             |
|--|------------------------------------|---|--|----------------------------------|-----------------------------|
|  |                                    |   |  | NEMA 1, 3R, 12<br>Product Number | NEMA 4/4X<br>Product Number |
| TQD, THQD                                  | Extended Shaft<br>4 5/16 - 14 5/16 | TQDHM2  | TQDOM2 <sup>2</sup>                        |                                  |                             |
|  | Shallow Mount<br>4 3/16            | TEFHM1  | TEFOM1                                     |                                  |                             |
| TEB, TEC, TB1,<br>TED, THED                | Extended Shaft<br>5-1/8 - 5 7/32   | TEFHM3  | TEFOM3                                     | TH1                              |                             |
|  | 5 1/8 - 5 13/16                    | TEFHM4  | TEFOM4                                     |                                  |                             |
|  | 5 1/8 - 15                         | TEFHM2  | TEFOM2                                     |                                  |                             |
| TFC, TFJ,<br>TFK, THFK                     | Shallow Mount<br>5 7/8             | TFKHM1  | TFKOM1                                     |                                  | THCH45 <sup>3,4</sup>       |
|  | Extended Shaft<br>6 7/8 - 15 1/2   | TFKHM2  | TFKOM2 <sup>2</sup>                        |                                  |                             |
| TJC, TJD, TJJ,<br>TJK, THJK,<br>TB4, TBC4  | Shallow Mount<br>5 7/8             | TJKHM1  | TJKOM1                                     | TH2                              |                             |
|  | Extended Shaft<br>5 5/8 - 15 5/8   | TJKHM2  | TJKOM2 <sup>4</sup>                        |                                  |                             |
| TKC, TKM,<br>THKM, TB6,<br>TBC6, TB8, TBC8 | Shallow Mount<br>7 7/16            | TKMHM1  | TKMOM1                                     |                                  |                             |
|  | Extended Shaft<br>7 1/32 - 17 5/16 | TKMHM2  | TKMOM2 <sup>4</sup>                        |                                  |                             |
| SE150 (GEH-5611) <sup>5</sup>              | 4 3/16                             | SEFHM1  | SEFOM1                                     | TH1                              |                             |
|  | 6 1/8 - 15                         | SEFHM2  | SEFOM2 <sup>2</sup>                        |                                  |                             |
| SF250 (GEH-5611) <sup>5</sup>              | 5 7/8                              | SEFHM1  | SEFOM1                                     |                                  | THCH45 <sup>3,4</sup>       |
|  | 7 3/4 - 15 1/2                     | SEFHM2  | SEFOM2 <sup>2</sup>                        |                                  |                             |
| SG600 (GEH-5653) <sup>5</sup>              | 5 7/8                              | SGHM1   | SGOM1                                      | TH2                              |                             |
|  | 5 5/8 - 15 5/8                     | SGHM2   | SGOM2 <sup>4</sup>                         |                                  |                             |
| SK1200 (GEH-5612) <sup>5</sup>             | 6                                  | SKHM1   | SKOM1                                      |                                  |                             |
|  | 7                                  | SKHM2   | SKOM2 <sup>4</sup>                         |                                  |                             |

<sup>1</sup>Handle assembly and operating mechanism separately packaged.

<sup>2</sup>For 15-inch long shaft order Product Number 788A831G10. For 20-inch long shaft order Product Number 788A831G20.

<sup>3</sup>Provides interlocking for J600, SG600 SK1200, and K1200 breakers when used with the extended shaft operating mechanism. For interlocking with E150/SE150, F225 and SF250 order special shaft Product Number 788A832G1.

<sup>4</sup>For 15-inch long shaft order Product Number 788A832G2. For 20-inch long shaft order Product Number 788A832G5.

<sup>5</sup>Installation instructions publication number.

<sup>6</sup>MOD 1 is 7 7/16; MOD 2 is 8 3/32.

<sup>7</sup>MOD 1 is 7 3/16 - 17 3/16; MOD 2 is 7 15/16 - 17 15/16.

### Handle Accessories for TDM Operating Mechanisms

| Device   | Product Number |
|--|----------------|
| Replacement neoprene gaskets<br>for NEMA 1, 3R and 12 enclosures |                |
| Use with TH1   | 788A742P3      |
| Use with TH2   | 788A742P4      |

