
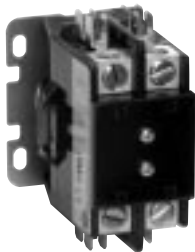
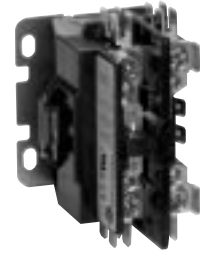


# Definite Purpose Contactors, 1-3 poles

## Standard Forms

On standard CR453C contactors, the coil and each power pole are supplied with two 1/4" quick connect terminals. Standard 20-35FLA contactors feature hex screws with #2 Phillips/slotted heads. Standard 40FLA contactors come with box lugs.

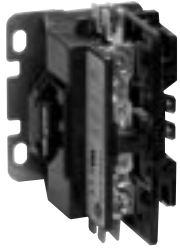

### CR453C Compact, 20A-40A, 1-pole, 1-pole plus shunted pole & 2-pole

Full Load Amps	Resistive Amps Per Pole	Locked Rotor Amps, Single Phase, 50/60 Hz			Poles	Catalog Number	List Price, GO-10DP
		240/277V	480V	600V			
20	30	120	100	80	1	CR453CA1*AA	\$24.00
					1 + Shunt	CR453CA3*AA	29.00
					2	CR453CA2*AA	32.00
25	35	150	125	100	1	CR453CB1*AA	30.00
					1 + Shunt	CR453CB3*AA	36.00
					2	CR453CB2*AA	40.00
30	40	180	150	120	1	CR453CC1*AA	32.00
					1 + Shunt	CR453CC3*AA	38.00
					2	CR453CC2*AA	42.00
35	50	180	150	120	1	CR453CD1*AA	35.00
					1 + Shunt	CR453CD3*AA	44.00
		210	175	140	2 <sup>Ⓢ</sup>	CR453CD2*AA	46.00
40	50	240	200	160	2 <sup>Ⓢ</sup>	CR453CE2*BB	57.00

Ⓢ Ratings shown are for 1-phase, 2-pole. See page 24 for 1-phase, 1-pole ratings.

### CR453C Compact Coil Selection (Replace \* in catalog number with appropriate coil digit)

Coil Voltage		Catalog Number Digit
60 Hz	50 Hz	
24	24	H
110-120	110	A
208-240	208-220	B
277	-	F

Factory Modified Forms p. 12  
 Field Installation Kits p. 24  
 Technical Data p. 27  
 Outline Drawings p. 30

www.GEindustrial.com