


Bath Fans, Bath Fan Accessories, Door Chimes

Product Selection – Bathroom Fan Single Units


Fan Type	Style	Effective Square Feet	Sones	Air Flow (CFM)	Product Number
Fan Only	Basic	60	3	50	BF50
Fan Only	Basic	75	3.5	60	BF60
Fan Only	Basic	85	4	70	BF70
Fan Only	Basic	145	4	120	BF120
Fan Only	Ultra Quiet	100	1.5	80	BF80UQ
Fan Only	Ultra Quiet	125	2	110	BF110UQ
Fan Only	Silent	100	1	80	BF80S
Fan and Light	Basic	85	4	70	BFL70
Fan and Light	Ultra Quiet	60	3	50	BFL50UQ
Fan and Light	Ultra Quiet	125	2.5	100	BFL100UQ
Fan and Light	Round with Nightlight	125	3.5	100	BFL100RNL
Fan, Light and Heater	Lexan Lens	85	3.5	70	BFLH70L
Fan, Light and Heater	Single Bulb Heater	85	3.5	70	BH70SB
Fan, Light and Heater	Dual Bulb Heater	85	3.5	70	BH70DB

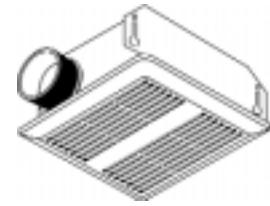

BF50, BF60, BF70



BFL100UQ

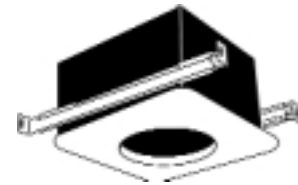


BH70SB

Product Dimensions

Product Number	Grill Dimensions (inches)	Housing Dimensions (inches)	Weight (Lbs.)
BF50	10.0 x 10.0	7 3/8 x 7 5/8 x 3 3/4	4.5
BF60	10.0 x 10.0	7 3/8 x 7 5/8 x 3 3/4	4.5
BF70	10.0 x 10.0	7 3/8 x 7 5/8 x 3 3/4	4.5
BF120	10.0 x 10.0	9 1/8 x 9 x 5 7/8	7.25
BF80UQ	11.0 x 13 3/4	10 3/4 x 9 1/4 x 7 7/8	10.0
BF110UQ	11.0 x 13 3/4	10 3/4 x 9 1/4 x 7 7/8	10.0
BF80S	11.0 x 13 3/4	10 3/4 x 9 1/4 x 7 7/8	10.0
BFL70	10 1/2 x 11.0	7 3/8 x 7 5/8 x 5 7/8	6.0
BFL50UQ	10 1/2 x 11.0	7 3/8 x 7 5/8 x 5 7/8	5.5
BFL100UQ	11 x 13 3/4	10 3/4 x 9 1/4 x 7 7/8	12.5
BFL100RNL	13 3/4 Round	9 1/4 x 9 1/8 x 5 7/8	12.0
BFLH70L	17 1/8 x 9 7/8	9 x 15 3/8 x 6 1/2	15.0
BH70SB	10 x 10	8 1/2 x 8 1/2 x 5 7/8	7.0
BH70DB	15 3/4 x 10	7 7/8 x 14 1/2 x 5 7/8	9.0

Product Selection – Bathroom Fan Contractor Pack-Multi Units

Product Description	Quantity	Weight (Lbs.)	Product Number
BF50 Fan Only	6	14	BF506PK
BF70 Fan Only	6	14	BF706PK
BFL50UQ Fan Only	4	14.75	BFL50UQ4PK
BFL70 Fan Only	4	14.75	BFL704PK
BF50-70, Housing Only	6	9.5	BF50/70HSG
BFL50-70, Housing Only	4	11.75	BFL50/70HSG

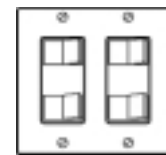


S44 Fan Switch

Product Selection – Bath Fan Accessory Fan Switch

Switch Type	Weight (Lbs.)	Product Number
Dual	0.3	S22
Triple	0.3	S33
Quadruple	0.5	S44

Product Selection – Door Chime

Chime Type	Quantity	Weight (Lbs.)	Product Number
Single Entry Lit	24	50	CL11
Single Entry Non-Lit	24	50	CNL11
Double Entry Lit	24	50	CL22
Double Entry Non-Lit	24	50	CNL22
Single Entry Lit, Stucco Button Only	1	0.5	CS11
Double Entry Lit, Stucco Button Only	1	0.5	CS22

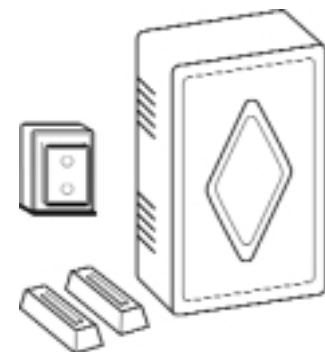

CL11, CL22, CS11, CS22 Door Chimes