


Pilot and Signaling Devices

Heavy-Duty 22.5 mm Watertight/Oiltight Selector Switches

C-2000

2- and 3-Position Knob Operated Selector Switches
Illuminated
600 VAC Max., 300 VDC Max.
10 Amps Continuous AC, 2.5 Amps Continuous DC

Selection Process

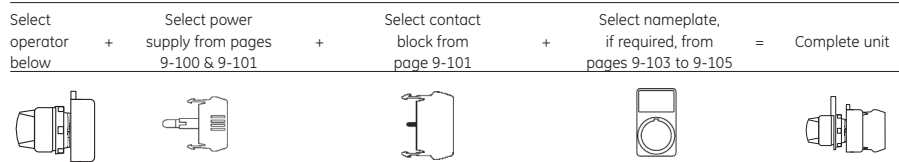

2- and 3-Position Illuminated Knob Operated Selector Switches

Knob Operated

Position Type	Operator Style	Release Type	Cam Code	Product Number	List Price GO-10GC
2-Position	Round Polished Chrome	Maintained	D	P9CSLD0*	\$18.50
2-Position	Round Satin Chrome	Maintained	D	P9MSLD0*	\$18.50
2-Position	Round Engineered Plastic	Maintained	D	P9XSLD0*	\$18.50
2-Position	Square Engineered Plastic	Maintained	D	P9SSLD0*	\$18.50
3-Position	Round Polished Chrome	Maintained	Z	P9CSLZ0*	\$18.50
3-Position	Round Satin Chrome	Maintained	Z	P9MSLZ0*	\$18.50
3-Position	Round Engineered Plastic	Maintained	Z	P9XSLZ0*	\$18.50
3-Position	Square Engineered Plastic	Maintained	Z	P9SSLZ0*	\$18.50
3-Position	Round Polished Chrome	Spring Return L → C	Z	P9CSLZ1*	\$26.00
3-Position	Round Satin Chrome	Spring Return L → C	Z	P9MSLZ1*	\$26.00
3-Position	Round Engineered Plastic	Spring Return L → C	Z	P9XSLZ1*	\$26.00
3-Position	Square Engineered Plastic	Spring Return L → C	Z	P9SSLZ1*	\$26.00
3-Position	Round Polished Chrome	Spring Return C ← R	Z	P9CSLZ5*	\$26.00
3-Position	Round Satin Chrome	Spring Return C ← R	Z	P9MSLZ5*	\$26.00
3-Position	Round Engineered Plastic	Spring Return C ← R	Z	P9XSLZ5*	\$26.00
3-Position	Square Engineered Plastic	Spring Return C ← R	Z	P9SSLZ5*	\$26.00
3-Position	Round Polished Chrome	Spring Return L → C ← R	Z	P9CSLZ3*	\$26.00
3-Position	Round Satin Chrome	Spring Return L → C ← R	Z	P9MSLZ3*	\$26.00
3-Position	Round Engineered Plastic	Spring Return L → C ← R	Z	P9XSLZ3*	\$26.00
3-Position	Square Engineered Plastic	Spring Return L → C ← R	Z	P9SSLZ3*	\$26.00

Replace asterisk (*) in product number with color code from Colors table below.

*Colors

Color	Red	Green	Yellow	Blue	White	Orange	Clear	No Knob ¹
*Color Code	R	V	G	L	B	A	I	0


¹When ordering operator without knob, deduct \$3.00 from List Price, GO-10GC. Color lenses are listed separately on page 9-112.

Cams

Note selection and position of contact block(s) according to operator type.

2-Position


†Cam Code				Screw Terminal Contact Block				Quick-Connect Terminal Contact Block	
				Position 1		Position 2		Position 1	Position 2
				Position 1	Position 2	Position 1	Position 2	Position 1	Position 2
D	0	—	X	—	P9B10VN	—	P9B10FN	—	—
	X	—	0	P9B01VN	—	—	P9B01FN	—	—
	0	—	X	P9B11VN	—	—	—	—	—
	X	—	0	—	—	—	—	—	—

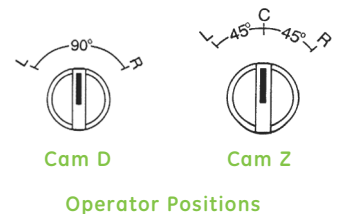

Note selection and position of contact block(s) according to operator type.

3-Position

†Cam Code				Screw Terminal Contact Block						Quick-Connect Terminal Contact Block	
				Position 1		Position 2		Position 1		Position 2	
				Position 1	Position 2	Position 1	Position 2	Position 1	Position 2	Position 1	Position 2
	0	0	X	P9B10VN	—	—	—	P9B10FN	—	—	—
	X	0	0	—	P9B10VN	—	—	—	P9B10FN	—	—
	X	X	0	P9B01VN	—	—	—	P9B01FN	—	—	—
Z	0	X	X	—	P9B01VN	—	—	—	P9B01FN	—	—
	0	0	X	—	—	—	—	—	—	—	—
	X	X	0	P9B11VN	—	—	—	—	—	—	—
	X	0	0	—	—	—	—	—	—	—	—
	0	X	X	—	P9B11VN	—	—	—	—	—	—

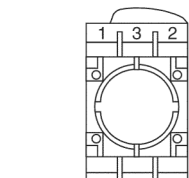

Contact Block Positions (viewed from rear)

†Cam code is 6th digit of product number.

