



On standard CR453A contactors, the coil and each power pole are supplied with two 1/4" quick connect terminals. Standard 25FLA and 30FLA contactors feature hex screws with #2 Phillips/slotted heads and short covers. Standard 40FLA contactors come with box lugs and long covers.

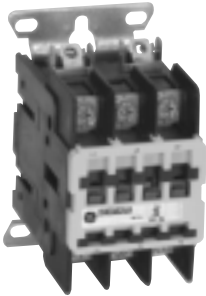

25A-30A
with screw terminals
and short cover

CR453A, 25A-40A, 2-pole & 3-pole

Full Load Amps	Resistive Amps Per Pole	Three Phase, 50/60 Hz						Single Phase HP, 50/60 Hz		Poles	Catalog Number	List Price, GO-10DP
		240V		480V		600V		120V	240V			
		HP	LRA	HP	LRA	HP	LRA					
25	35	7.5	150	10	125	10	100	2	3	2	CR453AB2*AA	\$47.00
										3	CR453AB3*AA	53.00
30	40	10	180	15	150	15	120	2	5	2	CR453AC2*AA	53.00
										3	CR453AC3*AA	59.00
40	50	10	240	20	200	20	160	3	7.5	2	CR453AD2*BB	64.00
										3	CR453AD3*BB	71.00

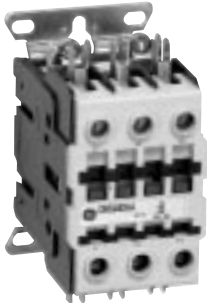

40A
with box lugs
and long cover

CR453A Coil Selection (Replace * in catalog number with appropriate coil digit)

Coil Voltage		Catalog Number Digit
60 Hz	50 Hz	
12	12	E
24	24	H
110-120	110-120	A
208-240	208-240	B
277	-	F
440-480	380-415	C
550-600	550-600	D