

GP15000E

GP SERIES
Commercial/Residential
Portable Generators

A/C Rated Output Watts 15,000
A/C Maximum Output Watts 22,500

Model 5734

UPC Number: 696471057348
Emissions Certification: 49-State



features

- GENERAC OHVI ENGINE, FULL PRESSURE LUBRICATION
- HIGH PERFORMANCE ALTERNATOR
- LARGE CAPACITY FUEL TANK FOR EXTENDED RUN TIME
- IDLE CONTROL
- CIRCUIT BREAKER PROTECTED OUTLETS
- LIFTING EYE
- FIXED HANDLES
- 12.3" PNEUMATIC WHEELS
- 1.25" HARDENED STEEL TUBE CRADLE
- LOW TONE MUFFLER

customer connections

Outlets


A	(1) Duplex 5-20R GFCI
B	(1) Duplex 5-20R 120V
C	(2) L5-30R
D	(1) L14-30R
E	(1) 12VDC
F	(1) 14-50R

Circuit Breakers

M	(2) 20A
N	(4) 30A
O	(1) 50A

Other Features

H	Hour Meter
I	Idle Control Switch

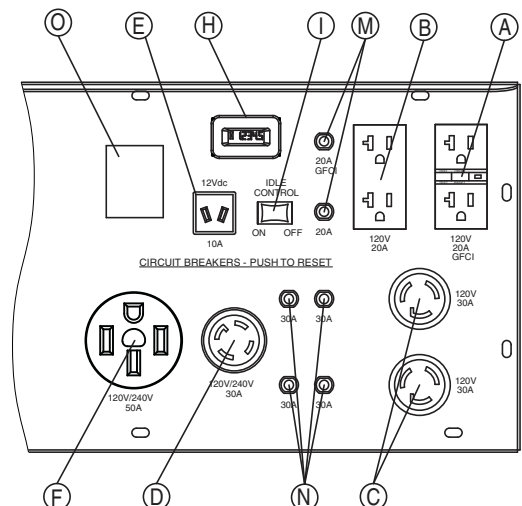

GP15000E

specifications

Product Series	GP15000E
Model	5734
Configuration/Emissions	49-State
A/C Rated Output Watts:	15,000
A/C Maximum Output Watts:	22,500
A/C Voltage	120/240VAC
A/C Frequency	60 Hz
Rated 120/240 VAC Amperage	62.5
Max 120/240 VAC Amperage	93.8
Neutrals	Not bonded to ground (Floating)
Engine Displacement	992cc
Engine Type	OHVI
Engine RPM	3600
Recommended Oil	SAE 30
Lubrication Method	Full Pressure
Choke Type	Manual Lever
Fuel Shut Off	Manual Lever
Idle Control	Yes
Starting Method	Electric
Battery	Included
Battery Size	12VDC 365 CCA
Low Oil Shutdown Method	Low Pressure

Start Switch Type	3-Position
Switch Location	On Engine
Single-Point Lifting Eye	Yes
Fuel Gauge	Built-in Tank
Fuel Tank Capacity (Gal)	16
Fuel Tank Capacity (Ltrs)	60.56
Run Time at 50% (Hours)	10
Cord Set	N/A
Handle Style	Fixed
Wheel type	12.3" Pneumatic Wheels
Maintenance Kit	Included
Warranty - Residential	2 Year
Warranty - Commercial	1 Year

dimensions and weights

Length (L)	48.5
Width (W)	31
Height (H)	39.5
Carton Length	49.25
Carton Width	23.25
Carton Height	31
Unit Weight (lbs)	363
Shipping Weight (lbs)	425

