

XG8000E

XG SERIES Commercial/Residential Portable Generators

Features

- **Generac OHVI® engine** incorporates full pressure lubrication with automotive style spin on oil filter for longer life engine.
- **Powerbar™** easily monitors power wattage.
- **Illuminated LED control panel** for improved visibility.
- **Hour meter** with maintenance resets tracks usage and monitors maintenance cycles.
- **Large-capacity steel fuel tank** with incorporated fuel gauge provides durability and extended run times.
- **Low-oil pressure shutdown** automatically safeguards engine from damage.
- **Covered outlets** provide added protection from the environment and adverse working conditions.
- **Full-wrap, heavy-duty, 1 1/4" steel tube cradle** for added durability and strength.
- **Heavy-duty, never flat wheels** for reliable portability.
- **User-friendly design** has conveniently placed engine controls for simple operation and east start-up.
- **Fold-down, locking handle** for sturdy portability and compact storage.
- **Single touch electric start**, battery included, provides hassle-free start-up.
- **Plug-in battery charger jack** to keep battery charged and ready to go.
- **First oil and maintenance kit included.**

Model 5747-3 696471057478
(EPA/49-State)


Model 5847-2 696471058475
(EPA/CSA-Canada)

Model 5846-1 696471058468
(EPA/CARB-California)



AC Rated Output Running Watts 8000
AC Maximum Output Starting Watts 10000

49-State Control Panel

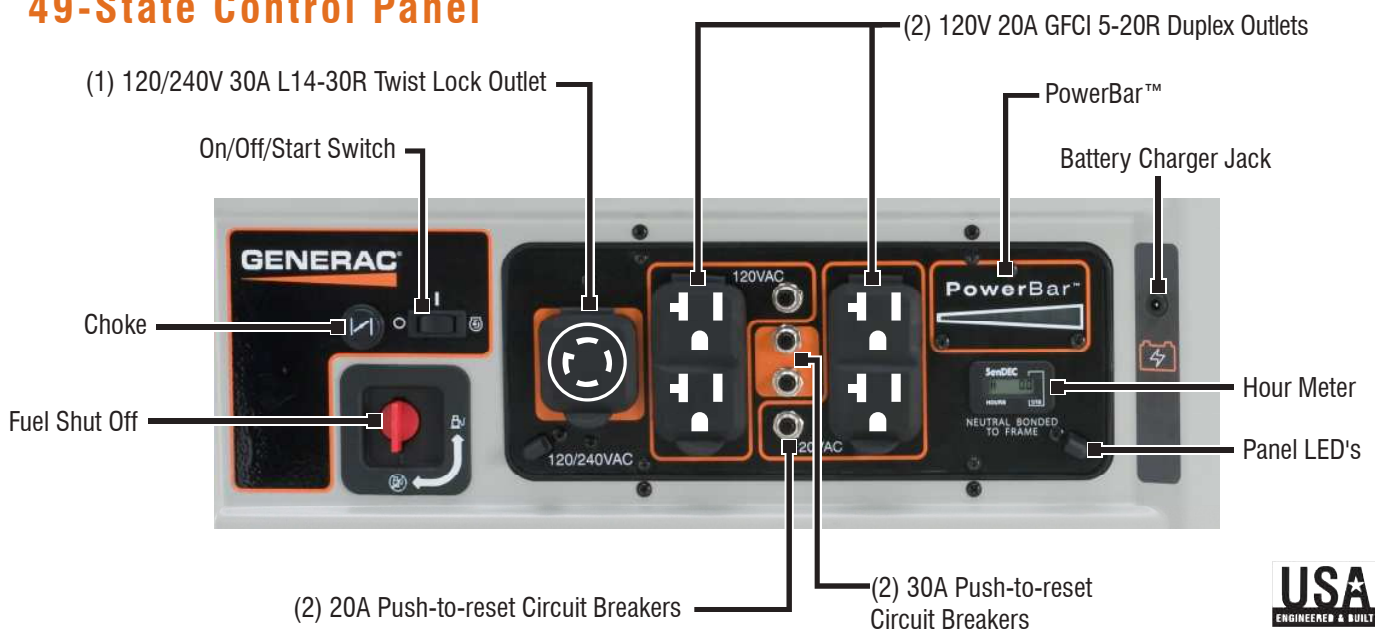

XG8000E

Specifications

Product Series	XG8000E
Model (Configuration)	5747-3 (EPA/49-State) 5847-2 (EPA/CSA-Canada) 5846-1(EPA/CARB-California)
AC Rated Output Running Watts	8000
AC Maximum Output Starting Watts	10000
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated 120/240 VAC Amperage	66.7/33.3
Max 120/240 VAC Amperage	83.3/41.6
Engine Displacement	407cc
Engine Type	OHVI
Engine RPM	3600
Recommended Oil	10W-30 / SAE 30
Lubrication Method	Oil Pump
Choke Location	On Control Panel
Fuel Shut Off	On Control Panel
Starting Method	Electric/Recoil Pull Start
Battery	Yes
Battery Type	12VDC 10 Ah
Battery Wall Charger Adapter	Included
Low Oil Shutdown	Low Pressure
Neutral Bonded to Ground	Yes

Start Switch Type	Off/On/Start
Switch Location	On Control Panel
Fuel Gauge	Built-in Tank
Fuel Tank Capacity Gal (Ltrs)	9 (34)
Run Time at 50% (Hours)	10
Handle Style	Folding Interlocked
Wheel Type	9.5" Semi-Solid Wheels
Maintenance Kit	Included
Warranty- Residential	2 Year
Warranty- Commercial	1 Year

Dimensions and Weights

Length in (mm)	31.5 (800)
Width in (mm)	25.5 (648)
Height in (mm)	28 (711)
Extended Length in (mm)	48.5 (1232)
Carton Length in (mm)	33 (838)
Carton Width in (mm)	26 (660)
Carton Height in (mm)	25 (635)
Unit Weight lbs (kg)	235 (107)
Shipping Weight lbs (kg)	250 (113)

